

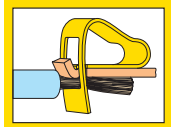
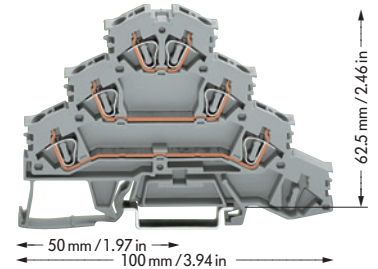


Rail-Mounted Quadruple Deck Terminal Blocks or Rail-Mounted Terminal Blocks for Wiring of Electric Motors Series 281

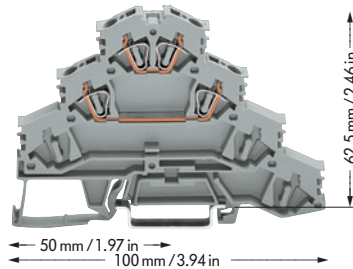

<p>0.08 – 4 mm² 400 V/6 kV/3 Ⓛ 20 A (2.5 mm²) 25 A (4 mm²)</p> <p>Terminal block width 6 mm / 0.236 in 8 – 9 mm / 0.33 in</p>	<p>AWG 28 – 12 300 V, 20 A</p>	<p>0.08 – 4 mm² 400 V/6 kV/3 Ⓛ 20 A (2.5 mm²) 25 A (4 mm²)</p> <p>Terminal block width 6 mm / 0.236 in 8 – 9 mm / 0.33 in</p>	<p>AWG 28 – 12</p>	<p>0.08 – 4 mm² 400 V/6 kV/3 Ⓛ 20 A (2.5 mm²) 25 A (4 mm²)</p> <p>Terminal block width 6 mm / 0.236 in 8 – 9 mm / 0.33 in</p>	<p>AWG 28 – 12</p>
--	------------------------------------	--	--------------------	--	--------------------

* GL BV LR NV

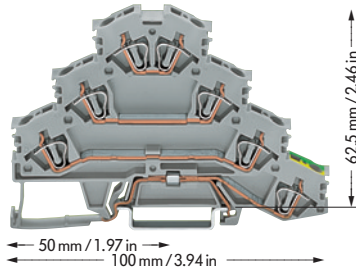

Item No.	Pack. unit pcs	Item No.	Pack. unit pcs	Item No.	Pack. unit pcs
Rail-mounted terminal block for wiring of electric motors or rail-mounted quadruple deck terminal block, for DIN 35 rail		Rail-mounted terminal block for wiring of electric motors or rail-mounted quadruple deck terminal block, for DIN 35 rail		Rail-mounted terminal block for wiring of electric motors or rail-mounted quadruple deck terminal block, for DIN 35 rail	
L1 – L2 – L3 – PE		L1 – L2		L1 – L2 – L3	
grey 281-530	50	grey 281-531	50	grey 281-532	50
End and intermediate plate, 1 mm / 0.039 in thick		End and intermediate plate, 1 mm / 0.039 in thick		End and intermediate plate, 1 mm / 0.039 in thick	
orange 281-366	100 (4 x 25)	orange 281-366	100 (4 x 25)	orange 281-366	100 (4 x 25)
grey 281-365	100 (4 x 25)	grey 281-365	100 (4 x 25)	grey 281-365	100 (4 x 25)

Accessories Series 281

Appropriate marking system **WMB/WSB** (see section 14)

Insulation stop Ⓛ, 5 pcs/strip	white 281-470 200 strips light grey 281-471 200 strips dark grey 281-472 200 strips	Insulation stop Ⓛ, 5 pcs/strip	white 281-470 200 strips light grey 281-471 200 strips dark grey 281-472 200 strips	Insulation stop Ⓛ, 5 pcs/strip	white 281-470 200 strips light grey 281-471 200 strips dark grey 281-472 200 strips
Comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-482 100 (4 x 25) 3-way 281-483 100 (4 x 25) 5-way 281-485 100 (4 x 25) 10-way 281-490 50 (2 x 25)	Comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-482 100 (4 x 25) 3-way 281-483 100 (4 x 25) 5-way 281-485 100 (4 x 25) 10-way 281-490 50 (2 x 25)	Comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-482 100 (4 x 25) 3-way 281-483 100 (4 x 25) 5-way 281-485 100 (4 x 25) 10-way 281-490 50 (2 x 25)
Alternate comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-492 100 (4 x 25)	Alternate comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-492 100 (4 x 25)	Alternate comb type jumper bar Ⓛ, insulated, I _N = I _N of terminal block	2-way 281-492 100 (4 x 25)
Operating tool , insulated	2-way 280-432 1 3-way 280-433 1 5-way 281-440 1	Operating tool , insulated	2-way 280-432 1 3-way 280-433 1 5-way 281-440 1	Operating tool , insulated	2-way 280-432 1 3-way 280-433 1 5-way 281-440 1
Test plug , with cable 500 mm / 17.7"	2 mm Ø, red 210-136 50 (5 x 10) 2.3 mm Ø, yel. 210-137 50 (5 x 10)	Test plug , with cable 500 mm / 17.7"	2 mm Ø, red 210-136 50 (5 x 10) 2.3 mm Ø, yel. 210-137 50 (5 x 10)	Test plug , with cable 500 mm / 17.7"	2 mm Ø, red 210-136 50 (5 x 10) 2.3 mm Ø, yel. 210-137 50 (5 x 10)
WMB multi-marking system , 10 strips with 10 markers each, white with black printing see section 14		WMB multi-marking system , 10 strips with 10 markers each, white with black printing see section 14		WMB multi-marking system , 10 strips with 10 markers each, white with black printing see section 14	
WSB quick marking system , 10 strips with 10 markers each, white with black printing see section 14		WSB quick marking system , 10 strips with 10 markers each, white with black printing see section 14		WSB quick marking system , 10 strips with 10 markers each, white with black printing see section 14	
Marker strips , transparent, plain, for central marking – group marking – 1 m / 3'33" long, 7.5 mm / 0.295 in wide	on roll 50 m 709-177 1 on roll 300 m 709-187 1	Marker strips , transparent, plain, for central marking – group marking – 1 m / 3'33" long, 7.5 mm / 0.295 in wide	on roll 50 m 709-177 1 on roll 300 m 709-187 1	Marker strips , transparent, plain, for central marking – group marking – 1 m / 3'33" long, 7.5 mm / 0.295 in wide	on roll 50 m 709-177 1 on roll 300 m 709-187 1

* For further approvals with corresponding ratings see section 15.