


C1812C683J1GACTU

aka C1812C683J1GAC7800

Capacitor, ceramic, 0.068 uF, +/-5% Tol, 100V, C0G, 1812

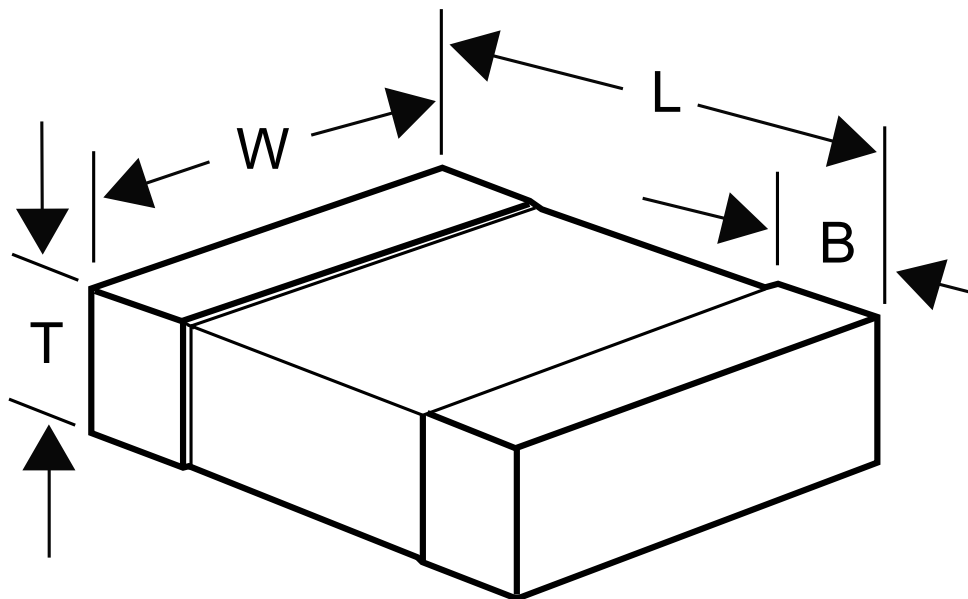

Dimensions (mm)

Specifications

ID	Dimension	Tolerance
L	4.50	+/-0.30
W	3.20	+/-0.30
T	1	+/-0.1
B	0.60	+/-0.35

Manufacturer:	KEMET
Capacitance:	0.068 uF
Chip Size:	1812
Voltage:	100V
Temperature Coefficient:	C0G
Tolerance:	+/-5%
Application:	Std Chip
Termination Type:	Tin
Marked:	No
Dissipation Factor:	0.1%
Insulation Resistance:	14.71 GOhm
Dielectric Strength:	250V
Package Kind:	T&R
Package Size:	7in
Package Type:	Plastic Tape
Package Quantity:	1000