
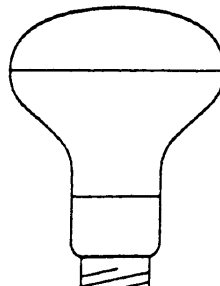


**Reflector**

(Diffuse)

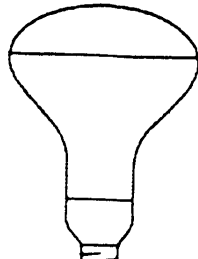

SES/E14 39mm	39	230-240	39	30R39/E14 230-240V	-	100	28738	3.16	2.75
SES/E14 50mm	25	240	50	25R50/SES 240V	180	50	31604	2.48	2.16
ES/E27 63.5mm	40	"	"	40R50/SES 240V	400	"	31615	2.48	2.16
BC/B22 63.5mm	40	"	63.5	40R63/ES 240V	"	50	31629	2.48	2.16
ES/E27 80mm	60	"	"	60R63/ES 240V	750	"	31663	2.48	2.16
	60	"	"	60R63/BC 240V	"	50	31648	2.48	2.16
	40	"	80	40R80/ES 240V	140	10	31674	2.48	2.16
	60	"	"	60R80/ES 240V	240	"	31707	2.48	2.16
	75	"	"	75R80/ES 240V	320	"	31718	2.48	2.16
	100	"	"	100R80/ES 240V	450	"	31744	2.48	2.16
BC/B22 80mm	60	"	"	60R80/BC 240V	240	"	31701	2.48	2.16
ES/E27 95mm	100	"	"	100R80/BC 240V	450	"	31735	2.48	2.16
	75	"	95	75R95/ES 240V	1000	32	28811	4.04	3.51
	100	"	"	100R95/ES 240V	1400	"	28816	4.04	3.51
ES/E27 125mm	150	"	125	150R125/ES 240V	2500	10	31511	5.92	5.15

Reflector Pallet Quantities - 39 Ø=5400 50 Ø=3000 63.5 Ø=2400

80 Ø=1400 95 Ø=540 125 Ø=250

Other Voltages available. Please contact our sales office

649314 → 649-454-