

651 096.

common technical characteristics

- Degree of protection up to IP 66.
- Smooth sides, painted light grey RAL 7035.
- Double insulated enclosure.
- Self-extinguishing enclosure.
- Sealing gasket.
- Stainless steel or plastic external fixings, depending on model.
- Sealable at 2 points.
- Wall mounting either directly through enclosure rear or externally using fixing lugs.
- Can be mounted on hinges.

PVC boxes



specific characteristics

- Degree of protection:
 - IP 66, except:
 - boxes ≥ 264 mm x 214 mm: IP 55,
 - boxes with hinges: IP 54.
- Resistance to external mechanical impact: IK 05.
- Service temperature: 0 to + 70 °C.

polycarbonate boxes

specific characteristics

- Degree of protection: : IP 66.
- Resistance to external mechanical impact: IK 07.
- Service temperature: 0 to + 140 °C.
- Terminal box or removable side plate, depending on model.

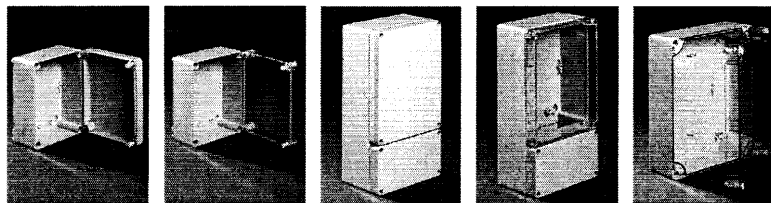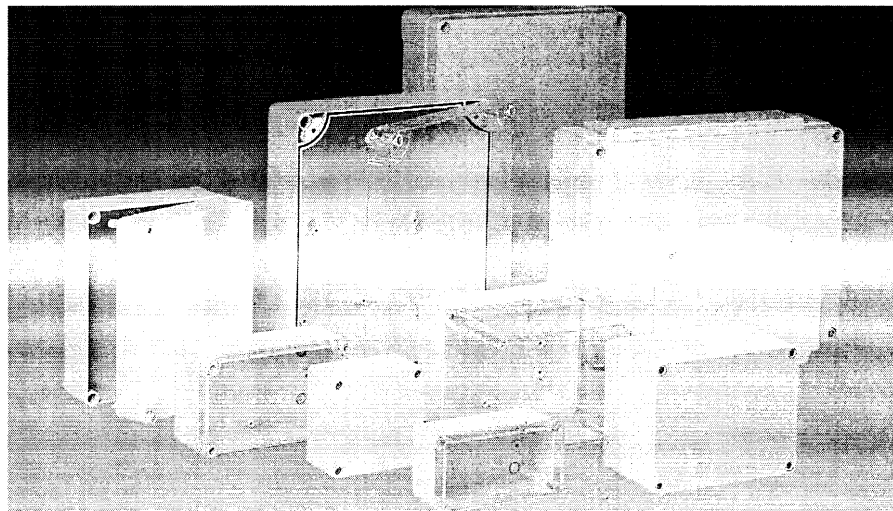

Internal dimensions in mm			PVC boxes with cover			Polycarbonate enclosures with cover			closure screws	pack qty
H	W	D	opaque	with hinges	transparent with hinges	opaque	transparent	with hinges		
100	100	55	02564	-	-	02565	02561	-	stainless steel	10/100
		130	02562	-	-	02566	-	-	stainless steel	5/50
105	70	48	03083	-	-	03085	03081	-	stainless steel	5/150
		80	03082	-	-	03086	-	-	stainless steel	5
129	239	66 (1)	-	-	-	03434	-	-	stainless steel	2
130	69	57	03187	-	-	03400	03401	-	stainless steel	6/84
		90	03182	-	-	-	-	-	stainless steel	6
164	99	67	03364	03370	-	03365	03361	-	plastic	2/52
		97	03367	-	-	03366	-	-	plastic	2/40
	129	70	03564	03570	03571	03565	03561	-	plastic	2/40
		91	03522	-	-	03525	03521	-	plastic	2/30
		130	03567	-	-	03566	-	-	plastic	2/18
		160	-	-	-	03450	03451	-	stainless steel	1
		224	-	-	-	-	03481	-	stainless steel	1
214	162	71	03640	-	-	03645	03641	-	plastic	1
		92	03624	03670	03671	03625	03621	-	plastic	1
		129	03627	-	-	03626	03623	-	plastic	1
264	214	91	03750	03770	-	03740	-	-	plastic	1
		110	03752	-	-	03760	03761	-	plastic	1
		150	-	-	-	03762	03763	-	plastic	1
300	240	100	03900	03905	-	03910	03911	03908	plastic	1
		150	03902	-	-	-	-	-	plastic	1
328	258	92	03884	03885	-	03881	03883	-	plastic	1
		92 (2)	-	-	-	03880	-	-	plastic	1
		151	03894	-	-	03891	03893	-	plastic	1

(1) Boxes with terminal box.

(2) Boxes with removable side plates.


selection table for accessories

internal dimensions in mm			mounting plate	wall fixing lugs	sealing caps
H	W	D			
100	100	55	–	09106	–
		130	–	09106	09150
105	70	48	–	–	09140
		80	–	–	09150
129	239	66	09154	–	–
130	69	57	–	09106	09140
		90	–	09106	09150
164	99	67	09135	09106	–
		97	09135	09106	–
		129	09154	09106	–
		70	09154	09106	–
		91	09154	09106	–
		130	09154	09106	–
		160	09154	09105	09150
214	162	224	09154	09105	09150
		71	09160	09106	–
		92	09160	09106	–
		129	09160	09106	–
264	214	91	09172	09106	–
		110	09172	09106	–
		150	09172	09106	–
300	240	100	09190	09106	–
		150	09190	09106	–
328	258	92	09188	09106	–
		151	09188	09106	–

accessories

plates


- Direct attachment in enclosure using self-tapping screws (included).
- 1.5 mm thick metal plate, zinc plated.

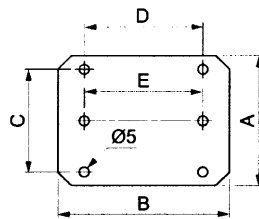

reference	A	B	C	D	E
09135	95	156	–	–	130
09154	120	156	65	130	–
09160	156	205	130	150	–
09172	208	258	161	221	–
09190	235	295	156	216	–
09188	250	320	210	250	–

set of 4 wall fixing lugs

- Material: steel, zinc bichromated.

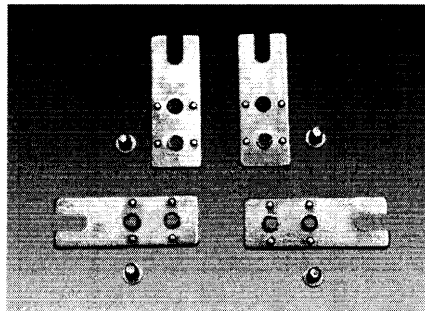

reference, plate	for boxes width	height	pack qty.
09135	164	099	1
09154	164	129	1
	239	129	1
09160	214	162	1
09172	264	214	1
09190	300	240	1
09188	328	258	1

reference, wall fixing lugs	for boxes	pack qty.
09105	160 and 224 mm deep	1
09106	for other depths	1