
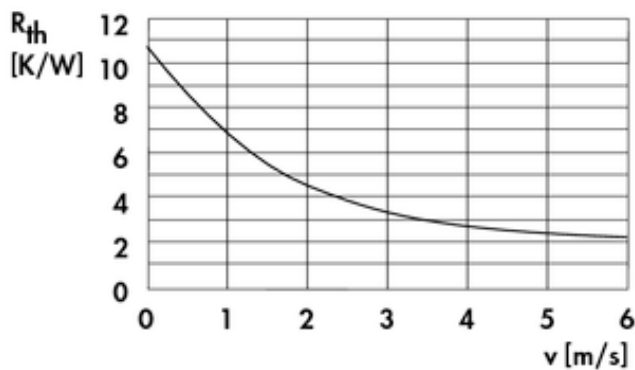


## Heatsinks for LEDs / **ICK LED R 45,7 x 16,5 G**

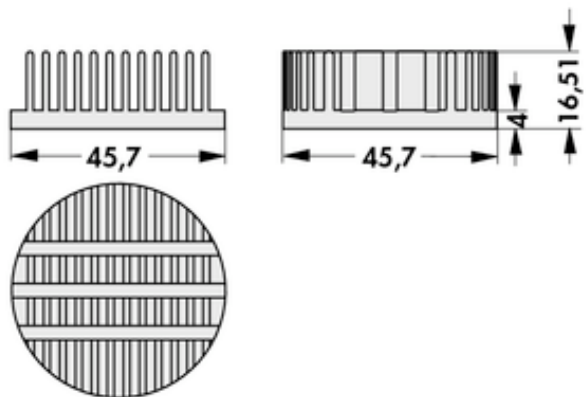

Ø 45,7 x 16,5 mm, for IC design LED

### Parameters of article **ICK LED R 45,7 x 16,5 G**

<b>R<sub>th</sub> [K/W]</b>	<b>i</b> 10.79
<b>dissipation loss [W]</b>	<b>i</b> 10.8
<b>mounting method</b>	therm. conductive foil / therm. cond. adhesive
<b>socket</b>	universal
<b>suitable for processor type</b>	universal
<b>Ø [mm]</b>	<b>i</b> 45.7
<b>height [mm]</b>	16.51
<b>plate thickness [mm]</b>	4
<b>surface treatment</b>	black anodised

### Accessories/ related articles

Thermally conductive foil both sides adhesive / **WLFT 404 D 45**

Thermally conductive foil both sides adhesive / **WLFT 405 D 45**