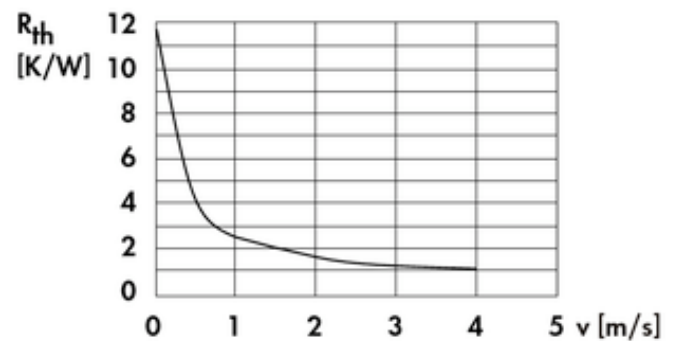
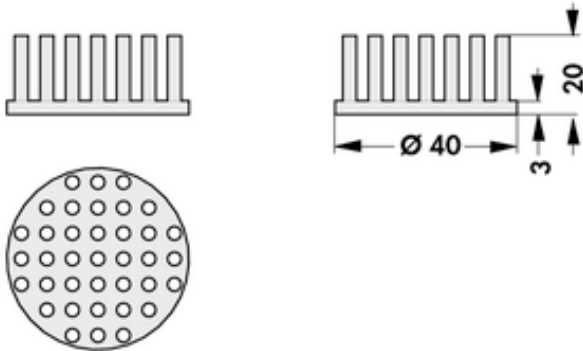
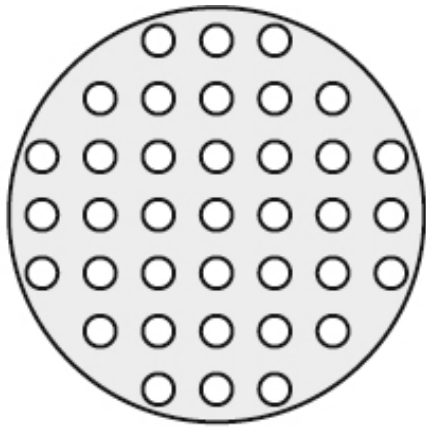


Pin heatsinks / **ICK S R A 40 x 20**

Ø 40 x 20 mm, pin heatsinks round

**Parameters of article ICK S R A 40 x 20**

<b>Bauform</b>	Rund
<b><math>R_{th}</math> [K/W]</b>	11.62
<b>dissipation loss [W]</b>	8.2
<b>mounting method</b>	therm. conductive foil / therm. cond. adhesive
<b>socket</b>	universal
<b>suitable for processor type</b>	universal
<b>Ø [mm]</b>	40
<b>height [mm]</b>	20
<b>plate thickness [mm]</b>	3
<b>weight [g]</b>	22.18

**Accessories/ related articles**

Thermally conductive foil both sides adhesive / **WLFT 404 D 40**

Thermally conductive foil both sides adhesive / **WLFT 405 D 40**