

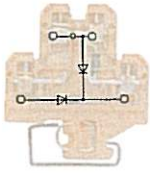



DK4 D
Arc suppression circuit for contactors and solenoid valves (DV)

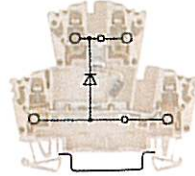



DK4 D WDK2.5 D
Arc suppression circuit for contactors and solenoid valves (DV)

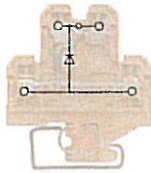

DK4 D
Arc suppression circuit for contactors and solenoid valves (DV)

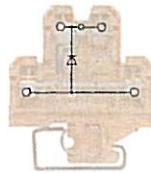

DK4 D WDK2.5 D
Diode terminal for lamp test circuits

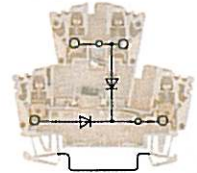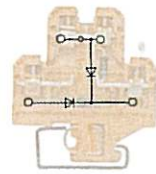

380V~
1000V
1A
10A
1N4007

380V~
1000V
1A
10A
1N4007

380V~
1000V
1A
10A
1N4007

380V~
1000V
1A
10A
1N4007

Beige
50mm

Beige or Blue	
DK4D	50mm
WDK2.5D	69mm
DK4D	56.5mm
WDK2.5D	63mm

Beige
50mm
56.5mm

Beige	
DK4D	50mm
WDK2.5D	69mm
DK4D	56.5mm
WDK2.5D	63mm

6mm
9mm

DK4D	6mm
WDK2.5D	5mm
DK4D	9mm
WDK2.5D	10mm

6mm
9mm

DK4D	6mm
WDK2.5D	5mm
DK4D	9mm
WDK2.5D	10mm

0.5...4mm ²
AWG 22...12

DK4D	0.5...4mm ²
WDK2.5D	0.5...2.5mm ²
DK4D	AWG 22...12
WDK2.5D	AWG 26...12

0.5...4mm ²
AWG 22...12

DK4D	0.5...4mm ²
WDK2.5D	0.5...2.5mm ²
DK4D	AWG 22...12
WDK2.5D	AWG 26...12

DK4Q	980161
DK4Q/35	980361

Beige		Blue	
DK4D	046796	DK4D	046798
DK4D/35	053886	DK4D/35	053888
WDK2.5D	102330		

DK4QD	980160
DK4QD/35	980360

DK4D	064276
DK4D/35	039666
WDK2.5D	102350

See page 12 - 1
See page 12 - 1
See page 12 - 1
See page 12 - 1
See page 12 - 1
See page 12 - 5