

AC Centrifugal Blowers Dual Inlet, Ø160mm



ebm-papst Mulfingen


- Dual Inlet fans with an external rotor motor offering the advantage of matched motor and impeller in a compact space saving design.
- Motors: IP44 rated, sealed for life, maintenance free, class B insulation, precision ball bearings and side mounted capacitor and terminal block.
- Impeller: forward curved multi-vane type force fitted for vibration free operation/efficient cooling.
- Body: heavy duty, galvanised steel
- May be mounted in any position

Nominal Data	Curve	Voltage	Frequency	Air Flow	Speed/rpm	Power Input	Current Draw	Noise	Perm. Amb. Temp.	Mass
Part Number	Curve	VAC	HZ	M ³ /h	min ⁻¹	W	A	DB(A)	°C	kg
D4E160-EG06-11	2	230 230	50 60	1240 1250	1300 1350	180 245	0.79 1.07	63 64	75 40	4.5

AC Centrifugal Blowers

Dual Inlet, Ø160mm

Performance Curve

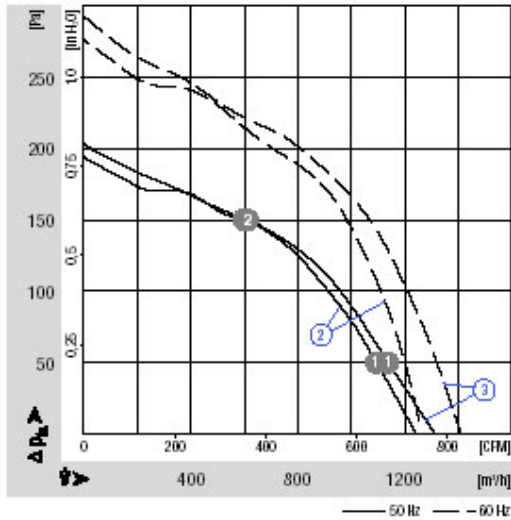

Dimensions

Part Number	I	J
D4E160-EG06-11	232	400

