



EDL Lighting limited

Redbrook Lane, Brereton, Rugeley, Staffordshire WS 15 1QU
Tel: 01889 582112 Fax: 01889 584012 e mail: sales@edl-lighting.co.uk
Web: www.edl-lighting.co.uk

Haloflex Luminaire

The Haloflex range is designed for maximum positioning flexibility in the head movement. The flexible gooseneck arm is either 150mm or 700mm long. A 12/24 volt 20 watt halogen lamp is supplied in either IP 21 or IP 54 version. The product is available with or without a transformer in the base. A range of accessories are available to increase the advantages of this luminaire

Version: HAL-L-IP21-20W-110/12V

Order Code 00633



Dimensional line drawing
when available

Primary voltage:	110v
Secondary voltage:	12V
Lamp type:	Halogen
Wattage:	20 watt
Lamp base type	
Switch fitted Yes/No:	Yes
Switch location:	On Head
IP Rating	IP21
Base Type:	Screw down
Fixing:	Can be horizontal or vertically mounted
No of arms:	1
Length of arms	700mm flexible
Arm Material:	Covered flexible steel
Shade size and material:	70mm diameter moulded plastic
Shield fitted:	No (available as accessory)
Shield material	Clear acrylic or polycarbonate
Visor fitted:	No
Articulation movement:	Flexible
Joint type:	Flexible
Trailing cable:	Yes
Plug fitted	No
Manufacturing Standard:	BS EN 60598
RHOS compliant	Not applicable
WEE Compliant	Not applicable
Finish & Colour:	Black



EDL Lighting limited

Redbrook Lane, Brereton, Rugeley, Staffordshire WS 15 1QU
Tel: 01889 582112 Fax: 01889 584012 e mail: sales@edl-lighting.co.uk
Web: www.edl-lighting.co.uk

The Haloflex range is designed for maximum positioning flexibility in the head movement. The flexible gooseneck arm is either 150mm or 700mm long. A 12/24 volt 20 watt halogen lamp is supplied in either IP 21 or IP 54 version. The product is available with or without a transformer in the base. A range of accessories are available to increase the advantages of this luminaire

Version: HAL-L-IP21-20W-110/12V

Order Code 00633

Features

Variety of Input voltages

Choice of arm lengths

20 watt halogen lamp fitted

Screw down base

Switch on head

Protective lens available (optional extra)

Option accessories include wall bracket, magnet, lens cover and clamp

Clamp



Protective Lens



Wall Bracket




Clamp Fitted to Base

Protective Lens Fitted to Head



Wall Bracket Fitted to Base

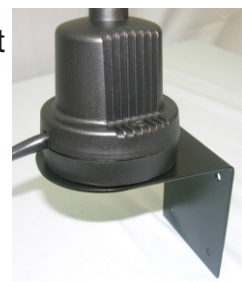

Magnet



Magnet Fitted to Base

