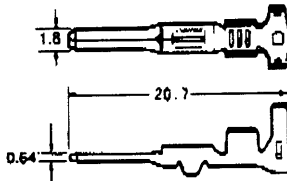
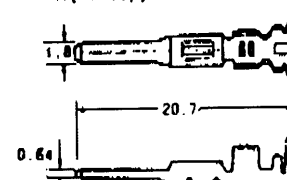




AMP .070 MULTILOCK Connectors

319-2234, 319-2260, 319-2283, 319-2295

Tab Contact

Contact	Wire Range	Wire Ins. Diameter	Material/Finish	Part No.				Hand Tool No. (Instruction Sheet)
				S.T.		L.P.		
				Brass	Phosphor Bronze	Brass	Phosphor Bronze	
.070Tab(For Cap)  Crimp Specifications : 114-5092	0.2—0.3mm ² (AWG#24—22)	∅1.4—1.9mm	Pretin	173633-1	173633-2	175029-1	175029-2	911799-2 (411-5481)
			Sel. Gold	—	173633-3	—	175029-3	
	0.5—1.25mm ² (AWG#20—16)	∅2.0—2.6mm	Pretin	173645-1	173645-2	175030-1	175030-2	911788-2 (411-5480)
			Sel. Gold	—	173645-3	—	175030-3	
.070Tab(For Cap)  For an extra-thin jacketed cable Crimp Specifications : 114-5167	0.3—0.5mm ² (AWG#22—20)	∅1.0—1.5mm	Brass/Pretin	175207-1	—	—	—	—
	0.5—1.25mm ² (AWG#20—16)	∅1.2—2.2mm	Brass/Pretin	175208-1	—	—	—	—

Receptacle Contact

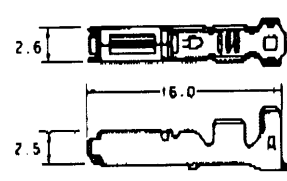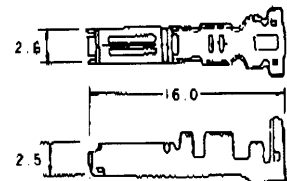Contact	Wire Range	Wire Ins. Diameter	Material/Finish	Part No.				Hand Tool No. (Instruction Sheet)
				S.T.		L.P.		
				Brass	Phosphor Bronze	Brass	Phosphor Bronze	
070Receptacle(For Plug)  Crimp Specifications : 114-5091	0.2—0.3mm ² (AWG#24—22)	∅1.4—1.9mm	Pretin	173630-1	173630-6	175026-1	175026-6	911799-2 (411-5481)
			Sel. Gold	173630-2	173630-7	175026-2	175026-7	
	0.5—1.25mm ² (AWG#20—16)	∅2.0—2.6mm	Pretin	173631-1	173631-6	175027-1	175027-6	911788-2 (411-5480)
			Sel. Gold	173631-2	173631-7	175027-2	175027-7	
070Receptacle(For Plug)  For an extra-thin jacketed cable Crimp Specifications : 114-5134	0.3—0.5mm ² (AWG#22—20)	∅1.0—1.5mm	Brass/Pretin	175124-1	—	—	—	—
	0.5—1.25mm ² (AWG#20—16)	∅1.2—2.2mm	Brass/Pretin	175095-1	—	—	—	—