

DCO7 brush control (silver/turquoise)

dyson

The cyclone with
no loss of suction

Consumer features and benefits:

The most powerful upright

- **Dyson Root⁸Cyclone™ technology** PATENTS PENDING
45% more suction than a Dual Cyclone.
- **Auto-adjusting cleaner head** PATENT PENDING
Adjusts automatically to the right height setting for all floors.
- **No filters to buy**
Lifetime highest grade filters without losing suction.
- **Anti-jam brushbar**
Brush control PATENT PENDING system protects rug tassels and belt. Can be switched off for delicate floors.
- **Ready-to-go hose** INVENTED BY DYSON
Goes straight to the top of the stairs. Doesn't fall over like others do.
- **High velocity airflow tools** PATENT PENDING
Draw more dust out of the carpet to clean stairs and upholstery better, and avoid sticking to curtains.
- **Remote trigger bin emptying** PATENTS PENDING
Quick and hygienic bin emptying.
- **Reversible wand** PATENT PENDING
Reaches awkward areas more easily and with a better grip.
- **2 year guarantee**

Specifications:

Product dimensions (mm):
H1172 x W355 x D340

Box dimensions (mm):
L971 x W369 x H250

Pallet dimensions (mm):
H1190 x W1000 x D12000

Pallet count: 12

Weight without on-board tools:
8.5kg

Operational weight: 8.63kg

Box weight: 10.1kg

Product code:

Retail: 04465-01

Mail order: 04465-02

Box barcode:

Retail: 5025155002377

Mail Order: 5025155002414


Maximum power input: 1400w

Cable length: 8.35m

Maximum reach: 13m

Suction power:

330 airwatts (constant)

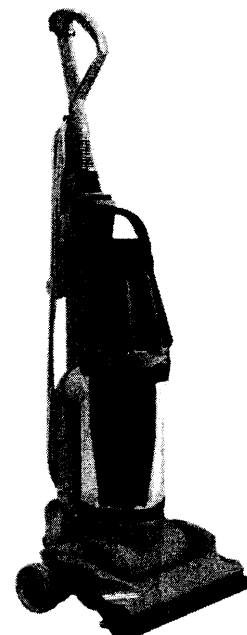

Notes

Consumer features and benefits should be used in full wherever possible.
To abridge text, please use emboldened, bulleted points (e.g. shelf-edge labels, catalogue listing text).
All text should be reproduced in given order of priority.

Please contact Dyson Trade Marketing on 01666 827200 for approval of all printed/published materials.