

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **2181121003**  
**Status:** **Active**  
**Overview:** PicoBlade Connector System  
**Description:** PicoBlade Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 300.00mm Length, 10 Circuits, Natural

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<u>218112</u>
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	PicoBlade-to-Pigtail
Overmolded	No
Overview	<u>PicoBlade Connector System</u>
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	195842250918


**Physical**

Cable Length	300.00mm
Circuits (Loaded)	10
Color - Resin	Natural
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	4.217/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28
Wire/Cable Type	UL 1061

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing 2181121000-000

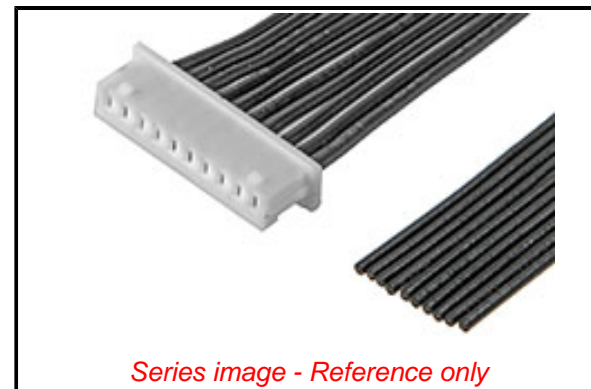

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

218112 Series

**Mates With**

PicoBlade Header [53261](#) , [53047](#) , [53398](#) ,  
[53048](#) . PicoBlade Plug Housing [51047](#)