

Lenovo® recommends Windows® 7 Professional.

lenovo® **FOR**
THOSE
WHO DO.

THE LENOVO® THINKCENTRE® M71z ALL-IN-ONE
INNOVATE. SUCCEED. SAVE.



BETTER PERFORMANCE -
GENUINE WINDOWS® 7 PROFESSIONAL

GREATER POWER - NEW 2ND GENERATION INTEL®
CORE i PROCESSORS (UP TO CORE i7)

FASTER ACCESS - OPTIONAL SSD OFFERS
FAST 15-SECOND BOOT TIME

BETTER PRODUCTIVITY - ADDITIONAL
MONITOR SUPPORT WITH DISPLAY PORT OUT

BETTER SECURITY - TRUSTED PLATFORM
MODULE ENCRYPTION CHIP (AVAILABLE IN
MOST LOCATIONS), AUTO PC LOCK, AND
KENSINGTON LOCK

BETTER MULTITASKING - VIEW MANAGEMENT
UTILITY SIMPLIFIES MULTIPLE DISPLAY USAGE

SUPERIOR GREEN CERTIFICATIONS - EPEAT GOLD,
ENERGY STAR 5.2, TCO CERTIFIED EDGE, AND EUP 2011

Introducing a sleek, simplified All-in-One (AIO) built for performance, security, and the environment. Designed for large enterprises and the public sector, the ThinkCentre M71z is built for business.

Innovate: The ThinkCentre M71z enables innovation by maximizing your workplace productivity. Connect an additional monitor with the Display Port out for better multitasking. Handle multiple displays efficiently with the View Management Utility. In addition, the M71z is designed to showcase long-term reliability and dependability – and make a statement about your business in classic style.

Succeed: ThinkCentre M71z is powered by a 2nd generation Intel® Core i processors with Genuine Windows® 7 operating system. It includes a wide 20" screen with visibly smart graphics and visuals built directly into the processor - all designed for powerful performance. Trusted Platform Module (TPM) support secures your business and personal data stored in the PC, while the Kensington Lock secures your PC to desk.

Save: The ThinkCentre M71z is designed to minimize both your costs of investment and ownership. Starting at a low price of USD \$599, the M71z is highly economical. Save time with under 15-second boot time with an optional SSD. The M71z also helps save the environment with several green certifications including EPEAT Gold, Energy Star 5.2, TCO Certified Edge, and EUP 2011.


The ThinkCentre M71z is designed with you as the inspiration – offering ease of comfort, high performance, and critical hardware and software security.



LENOVO ENHANCED EXPERIENCE 2.0 FOR WINDOWS® 7. FASTER AND OPTIMIZED FOR BUSINESS.

Lenovo Enhanced Experience 2.0 for Windows® 7 uses RapidBoot technology to start your PC on average 20 seconds faster than a typical Windows® 7 computer*. And with superior web conferencing and robust security features, you'll benefit from increased productivity at the office. Find out more at www.lenovo.com/win7ee

*Compares averaged data from Lenovo EE 2.0 PCs with averaged data from 42 competitor products of similar configuration. Testing conducted by CNET Labs, Beijing in November 2010, using the independent Microsoft VTS tool to measure start-up, shutdown, resume and other Windows® 7 performance measurements. Data from competitor and Lenovo PCs were averaged and compared to calculate the claims used. Performance will vary by model and configuration.

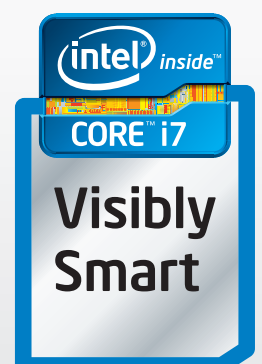

Lenovo® recommends Windows® 7 Professional.

lenovo® **FOR**
THOSE
WHO DO.

SUPERIOR SPEED

The ThinkCentre M71z allows you to work faster and more efficiently with:

- Genuine Windows® 7 Professional
- Intel's 2nd generation Core i platform, including Turbo Boost 2.0 and Hyper Threading technologies
- Incredible boot times – 27 seconds with SATA hard disk drive and a remarkable 15 seconds with an optional SSD

PROMOTING PRODUCTIVITY

The ThinkCentre M71z offers several features for enhanced display, allowing you to increase productivity with:

- Display port video-out, for connection to a secondary display screen
- The View Management Utility, so you can get the most out of a multiple display setup
- Communicator Utility, optimized camera and audio settings, and digital array microphone, enable seamless VoIP experience

SERVICE OFFERINGS

THINKPLUS® SUPPORT

Warranty Service and Support:

- All ThinkCentre customers receive Lenovo's award winning Warranty Service and Support.
- You can upgrade your existing base warranty, expand the term of your coverage and/or improve response time and level of service.
- This means you get a fixed-term, fixed-cost service solution that allows you to accurately budget for equipment expenses, matching your refresh cycles and critical support needs.

ThinkPlus Priority Support:

- Large enterprise operations require priority attention to support needs and need fast, expert product support to keep your business up and running.
- Lenovo's ThinkPlus Priority Support is an integrated product support solution that gives you and your staff direct access to the right level of technical support on the first call, making your priority our priority.
- Bypass basic troubleshooting and experience shorter hold times; reduced repair times and higher first time fix rates so that you and your staff can concentrate on mission-critical business activities.

STEADFAST SECURITY

The ThinkCentre M71z helps keep your data secure, offering a worry-free computing experience with:

- TPM helps keep your mission critical data secure
- The Kensington Lock helps prevent physical theft and tampering

EXTREMELY ECO-CONSCIOUS

The ThinkCentre M71z offers powerful computing with a commitment to the environment with:

- EPEAT Gold Certification – the M71z meets all the required certification criteria and over 75% of all optional criteria
- TCO Certified Edge – the M71z contains at least 50% recycled plastic materials
- EUP 2011 – the M71z consumes less electricity when in hibernation mode
- Energy Star 5.2 certification



THINKPLUS® PROTECTION


Lenovo Protection Services:

- Lenovo Protection Services for ThinkCentre protects you and your business against hard drive failure.

Lenovo Hard Disk Drive Retention:

- Lenovo Hard Disk Drive Retention allows you to retain your hard drive if it should happen to fail, instead of returning the damaged part to Lenovo, protecting valuable files and confidential information from falling into the wrong hands.
- To learn more about these and other available Lenovo Services, visit www.lenovo.com/services

THE LENOVO® THINKCENTRE® M71z ALL-IN-ONE

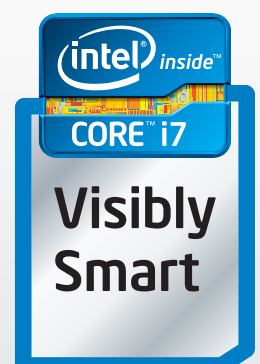

SOFTWARE OFFERINGS

SUPPORTED OPERATING SYSTEMS

- Genuine Windows® 7 Home Premium
- Genuine Windows® 7 Professional
- Genuine Windows® Vista Business²
- Genuine Windows® XP Professional¹

SUPPORTED TMT TOOLS

- View Management Utility
- Communication Utility
- Auto PC Lock
- System Update
- Rescue and Recovery
- Password Manager

 
PRE-LOADED APPLICATIONS

- Norton Internet Security 2011 (30-day trial)
- Microsoft Office 2010 Starter
- Skype® VoIP Software
- Adobe Acrobat Reader
- Adobe Flash Player

¹ Available in most regions
² Special Bid Only



OPTIONS AND ACCESSORIES



Lenovo PC3-10600 DDR3-1333 UDIMM Memory (2GB - 57Y4390; 4GB - 0A36527)



Lenovo PC3-10600 DDR3-1333 UDIMM Memory - 25 Pack (2GB - 57Y4420)



ThinkCentre Extend Arm (57Y4352)



Lenovo Ultralim Plus Wireless Keyboard & Mouse (0A340XX)



Lenovo Fingerprint USB Keyboard (73P47XX)



Lenovo USB Smartcard Keyboard (51J01XX)



ThinkPad USB Keyboard with TrackPoint (55Y90XX)



Lenovo Preferred Pro USB Keyboard (73P52XX)



Lenovo Enhanced Performance USB Keyboard (74P26XX)



Lenovo Laser Mouse (41U3074)



Lenovo USB Ultra Secure Memory Key (4GB - 57Y4327; 8GB - 57Y4328)



Lenovo Security Cable Lock (57Y4303)



Kensington Microsaver Security Cable Lock by Lenovo (73P2582)



DisplayPort to Single-Link DVI-D Monitor Cable (45J7915)



DisplayPort to VGA Monitor Cable (57Y4393)



ThinkPad USB 2.0 Portable Secure Hard Drive 320GB (43R2019)

SPECIFICATIONS

OPERATING SYSTEM Genuine Windows® 7 Starter Genuine Windows® 7 Home Premium Genuine Windows® 7 Professional	PROCESSOR Intel® Pentium® Dual-Core Processor 2 nd Generation Intel® Core i3 processor 2 nd Generation Intel® Core i5 processor	CHIPSET Intel® H61
DISPLAY 20" CCFL	GRAPHICS Integrated Intel® HD	MEMORY SUPPORT Up to DDR3 1333MHz
MEMORY SLOTS 2	MAXIMUM MEMORY 8GB	HDD Up to 1TB 3.5" SATA
SSD 160GB (Optional)	SLIM ODD DVD/Rambo	USB 6 (USB 2.0) - 2 on side, 4 in rear
RJ LAN PORT 1 (10/100/1000)	DISPLAY PORT DP out	MEDIA CARD READER 1 (standard)
ASSET ID Yes	TPM Yes	COVER LOCK Yes
KENSINGTON LOCK Yes	INTRUSION SWITCH Yes	WI-FI Yes (optional)
POWER SUPPLY 150W (85% efficiency, supports Energy Star 5.2)	INTEGRATED WEB CAMERA 2MP (optional)	INTEGRATED DIGITAL MICROPHONE ARRAY Yes (optional)
MULTI-TOUCH PANEL Yes (optional)	FRAME STAND Yes	VISUAL STAND Yes (optional)



 WWW.LENOVO.COM/EUROPE

©2011 Lenovo. All rights reserved.

Availability: Offers, prices, specifications and availability may change without notice. Lenovo is not responsible for photographic or typographic errors. **Warranty:** For a copy of applicable warranties, write to: Warranty Information, 500 Park Offices Drive, RTP, NC, 27709, Attn: Dept. ZPYA/B600. Lenovo makes no representation or warranty regarding third-party products or services. **Trademarks:** Lenovo, the Lenovo logo, Rescue and Recovery, ThinkCentre, ThinkVantage, and ThinkVision are trademarks or registered trademarks of Lenovo. Microsoft, Windows, and Vista are registered trademarks of Microsoft Corporation. Intel, the Intel logo, Intel Core, Core Inside, Xeon and Xeon Inside are registered trademarks of Intel Corporation in the U.S. and other countries. Other company, product, and service names may be trademarks or service marks of others.

Visit www.lenovo.com/safecomputing periodically for the latest information on safe and effective computing.

