


Part Number: [0039000041](#)
 Status: Active
 Overview: [Mini-Fit Jr. Power Connectors](#)
 Description: Mini-Fit Male Crimp Terminal, Tin (Sn) over Copper (Cu) Plated Brass Contact, 18-24 AWG, Bag

Documents:

図面 (PDF)	梱包仕様書 PK-5556-003 (PDF)
製品仕様書 PS-5556-001-001 (PDF)	Test Summary 55560000-TS-000 (PDF)
製品仕様書 PS-5556-002-001 (PDF)	RoHS Certificate of Compliance (PDF)
製品仕様書 TS-5556-002-001 (PDF)	

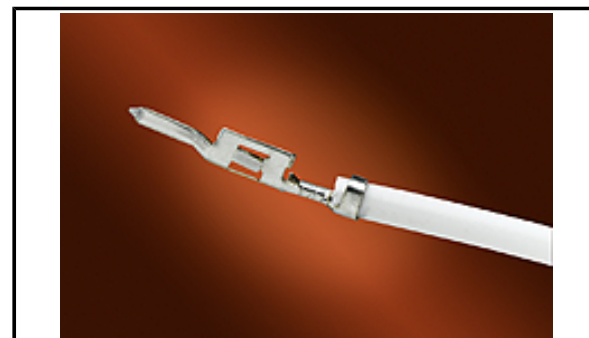

Series image - Reference only

一般用途	Power, 電線対電線
Crimp Quality Equipment	有
概要	Mini-Fit Jr. Power Connectors
梱包違い製品	39-00-0040 (Reel)
製品名	Mini-Fit
UPC	800753585034
機械的性能/材質	
耐久挿抜回数	30
ジェンダー	メール
材質 - 金属部	黄銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
Net Weight	123.000/mg
梱包形態	ポリ袋
嵌合部メッキ厚	0.889µm
ターミナルメッキ厚	0.889µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.30-3.10mm
電線サイズ (AWG)	18, 20, 22, 24
Wire Size mm ²	N/A
電気的性能	
最大定格電流	9.0A
最大定格電圧	600V
Solder Process Data	
Lead-freeProcess Capability	N/A
参考情報	
Engineering Number	5558TL
図面・仕様書情報	
梱包仕様書	PK-5556-003
製品仕様書	PS-5556-001-001, PS-5556-002-001, TS-5556-002-001
製品図面	SD-5558****
Test Summary	55560000-TS-000

EU ELV

Compliant

EU RoHS

[China RoHS](#)

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series
[5558 Series](#)

Mates With
[5556 Mini-Fit Crimp Terminal](#)

Use With
[5559 Mini-Fit Jr. Plug Housing](#), [30068 Mini-Fit TPA Plug Housing](#), [42475 Mini-Fit BMI Plug Housing](#)