

Part Number: [0449150021](#)
 Status: Active
 Overview: Magnetic and Modular Jacks and Plugs
 Description: Modular Plug, Category 6, Long Body, Shielded, 8/8, with Strain Relief

Documents:

3Dモデル [梱包仕様書 PK-44915-003 \(PDF\)](#)
 図面 (PDF) [RoHS Certificate of Compliance \(PDF\)](#)
 製品仕様書 PS-44915-003-001 (PDF)

Agency Certification

UL	E107635
一般	
コンポーネント種別	ワイヤープラグ
Magnetic	無
概要	<u>Magnetic and Modular Jacks and Plugs</u>
性能カテゴリ	6
パワーオーバーイーサネット (PoE)	N/A
製品名	Modular Plug 8/8, RJ45
UPC	800756395579

機械的性能/材質

色 - 樹脂部	無色
耐久挿抜回数	500
リバース / トップラッチ	N/A
Jack Height	N/A
ライトパイプ / LED	無
材質 - 金属部	りん青銅
材質 - 嵌合部メッキ	金
材質 - ターミナルメッキ	錫
材質 - 樹脂部	Polycarbonate
Net Weight	3.062/g
実装形態	N/A
位置決め	無
基板保持	無
梱包形態	ポリ袋
パネルマウント	N/A
ピッチ - 嵌合部 (インチ)	1.02mm
ピッチ - 実装部	1.02mm
ポート	1
極数 - 開口 / 実装	8/8
使用温度範囲	-40° to +85° C
実装スタイル	N/A
ケーブル種別	円形

電気的性能


最大定格電流	1.5A
パネルグラウンド	N/A
シールド	有
最大定格電圧	125V

Solder Process Data

Lead-free Process Capability	N/A
------------------------------	-----

参考情報

図面・仕様書情報

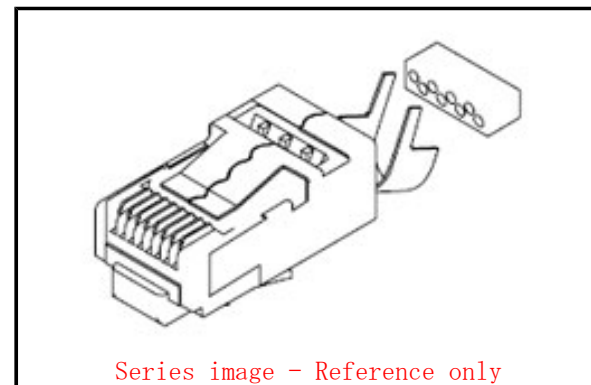

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Compliant

Not Contained

Search Parts in this Series
[44915 Series](#)

Mates With
FCC 68 Jacks

梱包仕様書
製品仕様書
製品図面

PK-44915-003
PS-44915-003-001
SD-44915-001

This document was generated on 10/02/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION