

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2065230161](#)
Status: **Active**
Overview: [Mini50 Connection Systems](#)
Description: Mini50 Unsealed Receptacle, Dual Row, UL94-HB, without CPA, 16 Circuits, Polarization Option A, Black

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-31301-538-001 \(PDF\)](#)
[Product Specification 2065230000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Housings
Series [206523](#)
Application Automotive, Power, Wire-to-Board
Overview [Mini50 Connection Systems](#)
Polarization A
Product Name Mini50
UPC 191130110018


Physical

Circuits (maximum) 16
Color - Resin Black
Gender Receptacle
Glow-Wire Capable No
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin PBT
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Pitch - Termination Interface 2.00mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +100°C

Material Info

Reference - Drawing Numbers

Packaging Specification PK-31301-538-001
Product Specification 2065230000-PS-000
Sales Drawing 2065230000-000

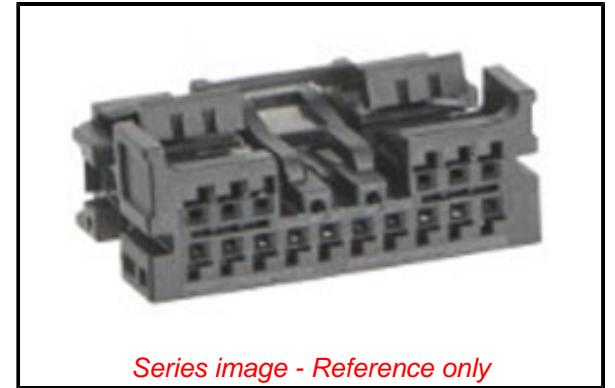

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[206523](#) Series

Mates With

Mini50 Surface Mount Header [348978160](#)
, [348979160](#)
 Mini50 Vertical Through-Hole Header [348250160](#) , [348259160](#)
 Mini50 Right-Angle Through-Hole Header [348260160](#) , [348269160](#)

Use With

CTX50 Unsealed Terminals [560023](#)