




msi

GRAPHICS CARDS GT 710 2GD3H LP

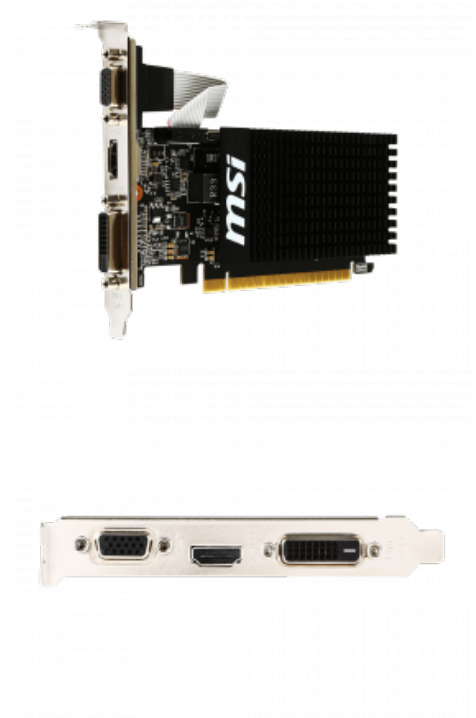

SPECIFICATIONS

Graphics Processing Unit	NVIDIA GeForce® GT 710
Interface	PCI Express 2.0 x16 (uses x8)
Core Clocks	954
Memory Speed	1600
Memory Size	2048
Memory Type	DDR3
Memory Bus	64-bit
HDCP Support	Y
Power consumption	19
Recommended PSU	300
Card Dimension(mm)	146 x 69 x 19 mm
Weight (Card / Package)	178
DirectX Version Support	12 API (feature level 11_0)
OpenGL Version Support	4.5
Maximum Displays	2
DVI Connectors	Dual-link DVI-D x 1 Max Resolution: 2560 x 1600 @60 Hz
D-SUB Connectors	1 1 (version 1.4a)
HDMI Connectors	Max Resolution: 4096x2160 @24 Hz
RAMDAC speed (MHz)	400

FEATURES

Core/Memory

- 954 MHz Core
- 2048MB DDR3 1600 MHz

Video Output Function

- Dual-link DVI-D x 1
- HDMI x 1 (Version 1.4a)
- D-Sub x 1