
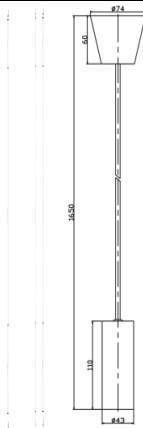


SYLVANIA**Product Name**

Product Parameters	Item	
	Product image (图片)	Line drawing
		
	Product code (产品型号)	LP-8096-4
	Sylvania model no.	0043372
	Product Name (产品名称)	pendant lamp brass
	LED brand & spec (品牌)	N/A
	LED Qty.(pcs)	N/A
	Circuit diagram(串并方式)	N/A
	Optic Parameters(材料)	N/A
Fixtures Basic Description	Input Voltages(V) (输入电压)	220-240V
	Frequency(Hz)(频率)	50/60Hz
	Maximum wattage(W) (最大功率)	25W
	Maximum voltage(V) (最大电压)	240V
	Electrical protection	Class I
	Lamp holder certification	CE
	Lamp holder flame retardant rating	NA
	Cable flame retardant rating	NA
	IP rating	20
	IK Rating	N/A
	Product certification	CE
	SDCM (色容差)	N/A
	Photometrics	N/A
	Driver output current (驱动输出电流)	N/A
	Driver output voltage (驱动输出电压)	N/A
	No-load power(驱动空载功率)	N/A
	Dimmable or not (调光)	N/A

Driver Parameter	Power factor(功率因数)	N/A
	Driver Certification (认证)	N/A
	Inrush current(冲击电流A)	N/A
	Inrush duration(持续时间 $\mu s = \text{micro seconds}$)	N/A
	Max qty for through wiring at 10A B Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 13A B Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 16A B Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 20A B Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 10A C Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 13A C Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 16A C Type breaker(最大的串接数量)	N/A
	Max qty for through wiring at 20A C Type breaker(最大的串接数量)	N/A
Housing parameters (壳体材料)	Metal	
Housing Color (壳体颜色)	Brass	
Textile cord colour	Black	
Textile cord length	1450mm	
Installation (安装方式)	Hanging	
Product Size	Length (mm)	1650mm
	Width (mm)	43mm(lampholder)
	Height (mm)	74mm(lampholder)
Life	Life time(Hrs) (灯具寿命)	N/A
	L70-B? or L80-B? or L90-B?	N/A
	Ambient Temperature (使用环境)	Indoor
	Warranty(year)(质保)	N/A