

## Start Surface Wall IP54

*START Surface Wall Square Deco IP54 430lm 840 BLK*  
0047057



### Product features

- Exterior surface wall light luminaire, Square shape, Black aluminium - RAL9005, 430lm, 8W, 54lm/W, 4000K, Driver current: 350mA, CRI80, 220-240V, IP54, IK07, 50.000 hrs (L70), (HxWxL) 54x130x166mm, Class I, Energy class: A++, A+, A



### PRODUCT OVERVIEW

IPC Code	0047057
Product name	START Surface Wall Square Deco IP54 430lm 840 BLK
Technology	LED
Housing	Aluminium
General application	Residential & Consumer
Certifications	EUNEW009
ETIM Class	EC002892
E-number FI	4579454
Fixture luminous flux (lm)	430
Luminaire efficacy (lm/W)	54
Colour temperature (K)	4000
Light colour	Neutral White
CRI (Ra)	80
Colour Variation Initial (SDCM)	6
Photobiological Risk Group	RG1
Total power consumption (W)	8
Electrical protection	Class I
Dimmable	No
LED Flickering Rate	High (>40%)
Average life (Nominal) (h)	50000
Housing colour	RAL 9005 - Jet black
IP rating	IP54
IK rating	IK07
Product EAN number	5410288470573
Lamps	No

### DATA TABLE

#### General data

IPC Code	0047057
Product name	START Surface Wall Square Deco IP54 430lm 840 BLK
Technology	LED
Housing	Aluminium
General application	Residential & Consumer

## Start Surface Wall IP54

*START Surface Wall Square Deco IP54 430lm 840 BLK*  
0047057

Operating temperature range (°C)	-20°C - 40°C
Certifications	EUNEW009
ETIM Class	EC002892
E-number FI	4579454

### Optical data

Fixture luminous flux (lm)	430
Luminaire efficacy (lm/W)	54
Colour temperature (K)	4000
Colour Code	840
Light colour	Neutral White
CRI (Ra)	80
Colour Variation Initial (SDCM)	6
Photobiological Risk Group	RG1

### Electrical data

Total power consumption (W)	8
Current (A)	0.04
Mains voltage (V)	220-240V~
Lamp power factor	0.84
THD (at 230 V, 50 Hz, full load, at 100% dimming level) xx.x %	15.0
Electrical protection	Class I
Dimmable	No
Drive current (mA)	350
Inrush Current (A)	10
Inrush Duration (µs)	200
Nominal Frequency (Hz)	50/60Hz
LED Flickering Rate	High (>40%)
Max. Luminaires per 10A C Breaker	80
Max. Luminaires per 13A C Breaker	115
Max. Luminaires per 16A C Breaker	125
Max. Luminaires per 20A C Breaker	160

### Lifetime data

Lumen maintenance - L70 B50	50000
Lumen maintenance - L80 B50	35000
Lumen maintenance - L80 B20	32000
Lumen maintenance - L80 B10	28000
Lumen maintenance - L90 B50	25000
Lumen maintenance - L90 B20	20000
Lumen maintenance - L90 B10	15000
Average life (Nominal) (h)	50000

### Physical data

Housing colour	RAL 9005 - Jet black
IP rating	IP54
IK rating	IK07
Diffuser finish	Transparent

## Start Surface Wall IP54


*START Surface Wall Square Deco IP54 430lm 840 BLK*  
0047057

Diffuser material	Glass
Nominal Product Length (mm)	167
Nominal Product Width (mm)	130
Nominal Product Height (mm)	54
Weight (kg)	0.6


### Packaging

Single packaging type	Carton
Product EAN number	5410288470573
Packaging single length / height (cm)	14.0
Packaging single width (cm)	6.5
Packaging single depth (cm)	18.0
DUN14 (outer)	15410288470570
Units per outer package	10
Packaging outer length / height (cm)	35.5
Packaging outer width (cm)	30.0
Packaging outer depth (cm)	19.5

## PHOTOMETRY

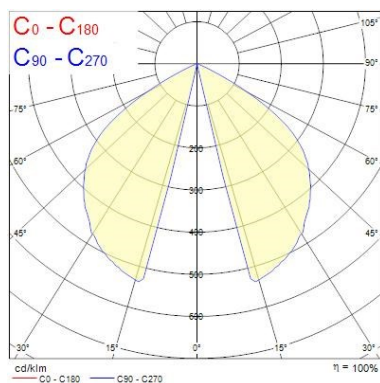


## TECHNICAL DRAWINGS

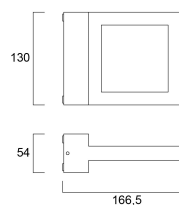


## Start Surface Wall IP54


START Surface Wall Square Deco IP54 430lm 840 BLK  
0047057


**SYLVANIA** 0047057


 This luminaire contains built-in LED lamps

 } LED


The lamps cannot be changed in the luminaire.

874/2012 

 This luminaire contains built-in LED lamps

 } LED

The lamps cannot be changed in the luminaire.

**SYLVANIA** 0047057 

874/2012