

Product Specifications

PGA48 Cardioid Dynamic Vocal Microphone

Overview

The PGA48 Dynamic Vocal Microphone is a professional quality microphone featuring highly durable design and construction that delivers excellent sound. Ideal for use in spoken word and karaoke performance, the PGA48 features an on/off switch, swivel adapter, zipper pouch and choice of XLR cable or QTR (¼") cable, or without cable.

Features

- Tailored microphone cartridge design specifically for clarity in the standard frequency range of speech
- Cardioid polar pattern picks up audio from the source while rejecting unwanted noise
- Updated industrial design with black metallic finish and classic silver ball grille
- Available with and without XLR Cable for flexibility in gear choice
 - 15 ft (4.6 m) XLR-XLR cable
 - 15 ft (4.6 m) XLR-QTR cable
 - Also available without cable
- On/Off switch for discrete control of microphone operation
- Stand adapter for mounting to a microphone stand
- Zipper pouch included for additional protection during storage or transport
- Legendary Shure quality design and construction for exceptional performance in rigorous environments



PGA 48

Product Specifications

Type	Dynamic (moving coil)
Frequency Response	70 to 15,000 Hz
Polar Pattern	Cardioid
Output Impedance	600 Ω
Sensitivity <i>at 1 kHz, open circuit voltage</i>	-53.5 dBV/Pa (2.10 mV) <i>1 Pa=94 dB SPL</i>
Polarity	Positive pressure on diaphragm produces positive voltage on pin 2 with respect to pin 3
Weight	300 g (10.58 oz)
Connector	Three-pin professional audio (XLR), male
Operating Temperature	-20 to 165 °F (-29 to 74 °C)
Operating Humidity <i>Relative</i>	0 to 95%


Available SKUs

PGA48-LC	Microphone, clip, stand adapter, and pouch (Less cable)
PGA48-XLR	Microphone, clip, stand adapter, pouch and 15 ft (4.6 m) XLR-to-XLR cable
PGA48-QTR	Microphone, clip, stand adapter, pouch and 15 ft (4.6 m) XLR-to-1/4" cable


Accessories

A25D	Break-resistant microphone clip
A58WS	Black foam windscreen
31A1856	5/8" to 3/8" thread adapter
C25J	25 ft (7.6 m) XLR-to-XLR cable
RPMP48G	Replacement PGA48 silver mesh grille

Polar Pattern

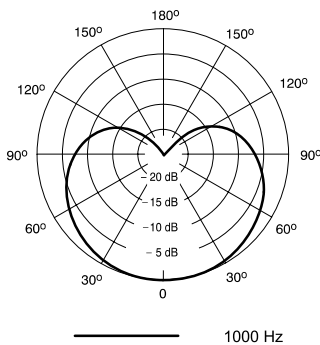

Frequency Response

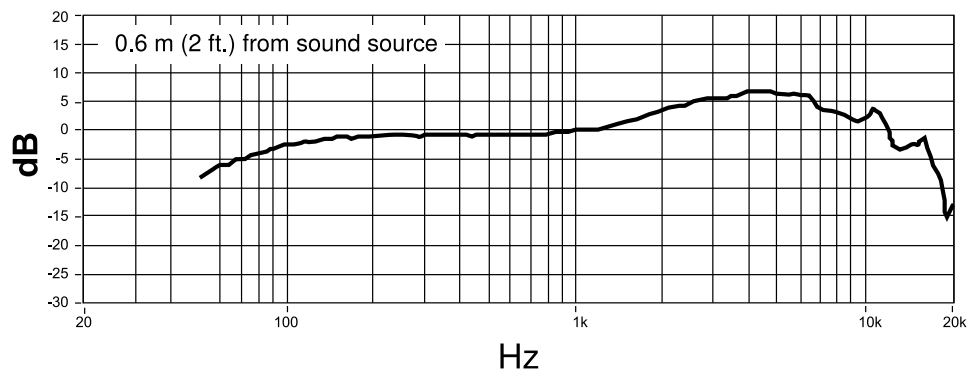

SHURE[®]

LEGENDARY
PERFORMANCE™

www.shure.com

© 2015 Shure Incorporated