


### SPECIFICATION SHEET

PRODUCT CODE: 778357

This eye-catching Up/Down Garden Wall Light will work well on a wall or porch to provide extra light. The cool white light is distributed both up and down, giving the product a great contemporary finish. Constructed using aluminium, this outdoor light is durable and provides an 800-lumen light output. With an IP54 rating, the fitting is suitable for outdoor use in any modern or contemporary setting.



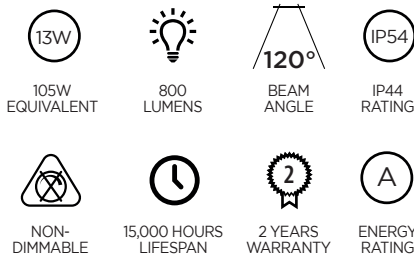


### SPECIFICATION

Product code	778357
Fitting	Garden Light
Bulb shape	SMD
Wattage	13.2W
Equivalent wattage	105W
Lumens	800lm
Ra	80
Dimmable	No
Beam Angle	120°
Width	150mm
Height	227mm
Depth	130mm
Lifespan	15,000 hours
Warranty	2 Years
Energy consumption	0.0132kW/h
Input frequency	50Hz
Voltage	230-240V
Energy rating	A
Material	Aluminium Body + PC Cover
Packaging	White Box + Colour Label

### OPTICAL TEST PARAMETERS

Voltage	230-240V
Current	0.07A
Power	13.2W
CCT	No
Ra	80
Lumens	800lm
Lumens per watt	60lm/W
Colour tolerance	<6
Power factor	0.5

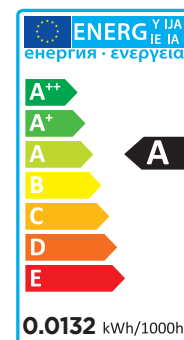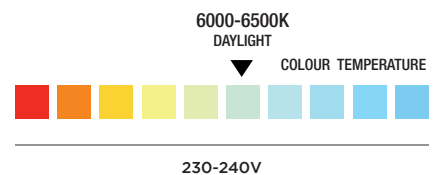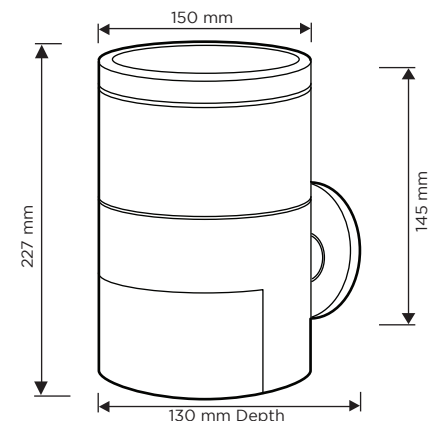

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT  
 T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



October 2019