




# USB Office Headset Pro Stereo

Item no.:

# 126-13

EAN:

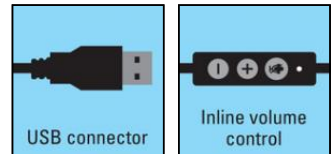






The Sandberg USB Office Headset Pro Stereo is of outstanding quality and can be used for, e.g. your home office, workplace or studying. The microphone is on a flexible arm, which ensures that the other person can hear you clearly. A speaker for each ear also means that reproduction of the other person's speech is clear and distinct. The discreet lightweight construction with soft ear pads and adjustable headband provides you with optimal comfort. Built-in max. volume of 118 db to avoid damage to your hearing. Connects through a USB port and works immediately. Inline volume control.

More information:  
 [www.sandberg.world](http://www.sandberg.world)



# Sandberg USB Office Headset Pro Stereo

## Specifications

Cable length: 2.1 metres	
Connector: 1 x USB A Male plug	
Earphone:	
Driver unit: 30 mm	
Frequency range: 20 Hz - 7 kHz	
Microphone:	
Type: 2.7 mm dia. electret condenser microphone	
Direction: Uni-directional	
Frequency Response: 50 Hz - 16 kHz	
Sensitivity: -40 dB ± 3 dB	
Compatible with:	
 Windows 10	
 Windows 8	
 Windows 7	
 Windows Vista	
 MacOS	



## Packaging info



## Dimensions

	Product	Package
Height (cm)		24.00
Width (cm)		18.00
Depth (cm)		9.00
Weight (g)		200.00



Product:  
[www.sandberg.world/product/usb-office-headset-pro-stereo](http://www.sandberg.world/product/usb-office-headset-pro-stereo)



Dealer: