


STELLAR 6.5W ADJUSTABLE LED DOWNLIGHT

SPECIFICATION SHEET

PRODUCT CODE: 769416

Brighten up your space with this Adjustable LED downlight bezel in gloss white. Designed so the standard size SMD LED bulb can be tilted for preference, the circular design has a 38° beam angle and IP20.

Create a modern look in your kitchen, living room and hallway with this fast and efficient screw to fit installation. The downlight projects up to 500 lumens of cool white light. Supplied with a driver and a lifespan of 15,000 hours. Bulbs are not included.



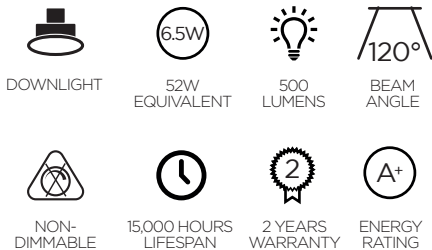


SPECIFICATION

Product code	769416
Fitting	Downlight
Bulb Shape	SMD
Wattage	6.5W
Equivalent wattage	52W
Lumens	500lm
Ra	80
Dimmable	No
Beam Angle	120°
Diameter	Ø90mm
Height	45mm
Lifespan	15,000 hours
Warranty	2 Years
Energy consumption	6.5kWh/1000h
Input Frequency	50Hz
Voltage	100-240V
Energy rating	A+
Material	PPT body (Aluminum inside)
Packaging	White Box + Colour Label
IP Rating	IP20

OPTICAL TEST PARAMETERS

Voltage	100-240V
Current	0.05mA
Power	6.5W
CCT	4000-4500K
Ra	80
Lumens	500lm
Lumens per watt	80lm/W
Colour tolerance	<6
Power factor	0.5

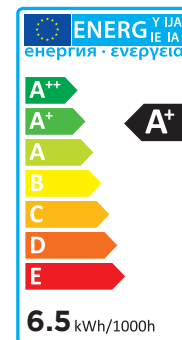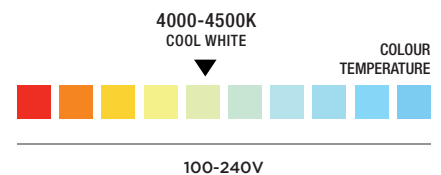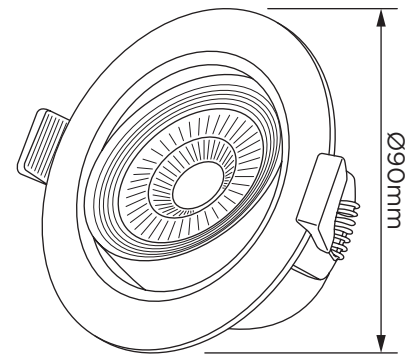

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT
 T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk

