

TIME LED®

STELLAR 10W MINI PANEL INTERCHANGEABLE LED DOWNLIGHT - SILVER/WHITE

SPECIFICATION SHEET

PRODUCT CODE: 769515

Brighten up your space with this Mini Panel interchangeable LED downlight bezel. With a quick twist-and-lock design you can easily switch from a white to silver finish, allowing you to redecorate the ceiling.

Accommodating standard size SMD LED bulbs, the casing is manufactured from die cast aluminium with a circular design. Create a modern look in your kitchen, living room and hallway with this fast and efficient screw to fit installation. Supplied with a driver and a lifespan of 15,000 hours.



DOWN LIGHT



10W = 80W



700 LUMENS



DIMMABLE



DOWNLIGHT



80W EQUIVALENT



700 LUMENS



110° BEAM ANGLE



DIMMABLE



15,000 HOURS LIFESPAN



2 YEARS WARRANTY






ENERGY RATING

SPECIFICATION

Product code	769515
Fitting	Downlight
Bulb Shape	SMD
Wattage	10W
Equivalent wattage	80W
Lumens	700lm
Ra	80
Dimmable	Yes
Beam Angle	110°
Diameter	Ø110mm
Height	55mm
Lifespan	15,000 hours
Warranty	2 Years
Energy consumption	10kWh/1000h
Input Frequency	50Hz
Voltage	220-240V
Energy rating	A+
Material	PBT Body (Aluminium Inside)
Packaging	White Box + Colour Label
IP Rating	IP44

OPTICAL TEST PARAMETERS

Voltage	220-240V
Current	0.05mA
Power	10.1W
CCT	4000-4500K
Ra	80
Lumens	700lm
Lumens per watt	66.34lm/W
Colour tolerance	<6
Power factor	0.5

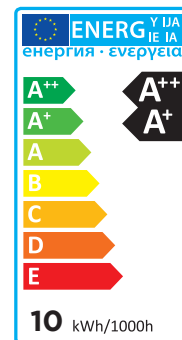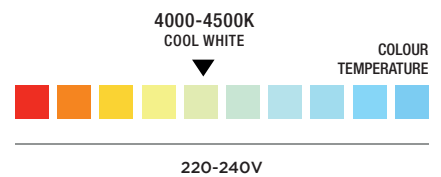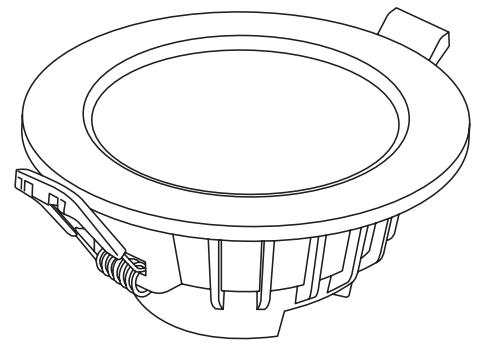

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT
T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



SPEC_769515_V1_JULY2020