

P180 Plus

Earbuds with Remote and Mic



Features

- Integrated acoustic cavity designed for outstanding sound quality with punchy bass and clear treble
- 14.2mm magnetic NdFeB drivers ensure excellent audio performance
- High-sensitivity omni-directional microphone ensures the clarity of phone calls
- Three-button wired controller for easy operation from music to calls



Specifications

Driver unit	Φ14.2mm NdFeB driver
Frequency response	20Hz-20KHz
Sensitivity	97dB
Impedance	32Ω
Cable length	1.2m
Cable connector	3.5mm/4 pole/straight

****The specifications and functions are subject to the finalized product on the market.***




P180 Plus

Package Graphic Design

Package Info	
Inner Carton	75mm×33.5mm×121mm (L×W×H), 38.8g (gross weight)
Master Carton	356mm×316mm×263mm (L×W×H), 3.71Kg (gross weight)
PCS/CTN	80

**This Package Info of domestic product is for reference only and the actual carton size/weight may slightly differ.*

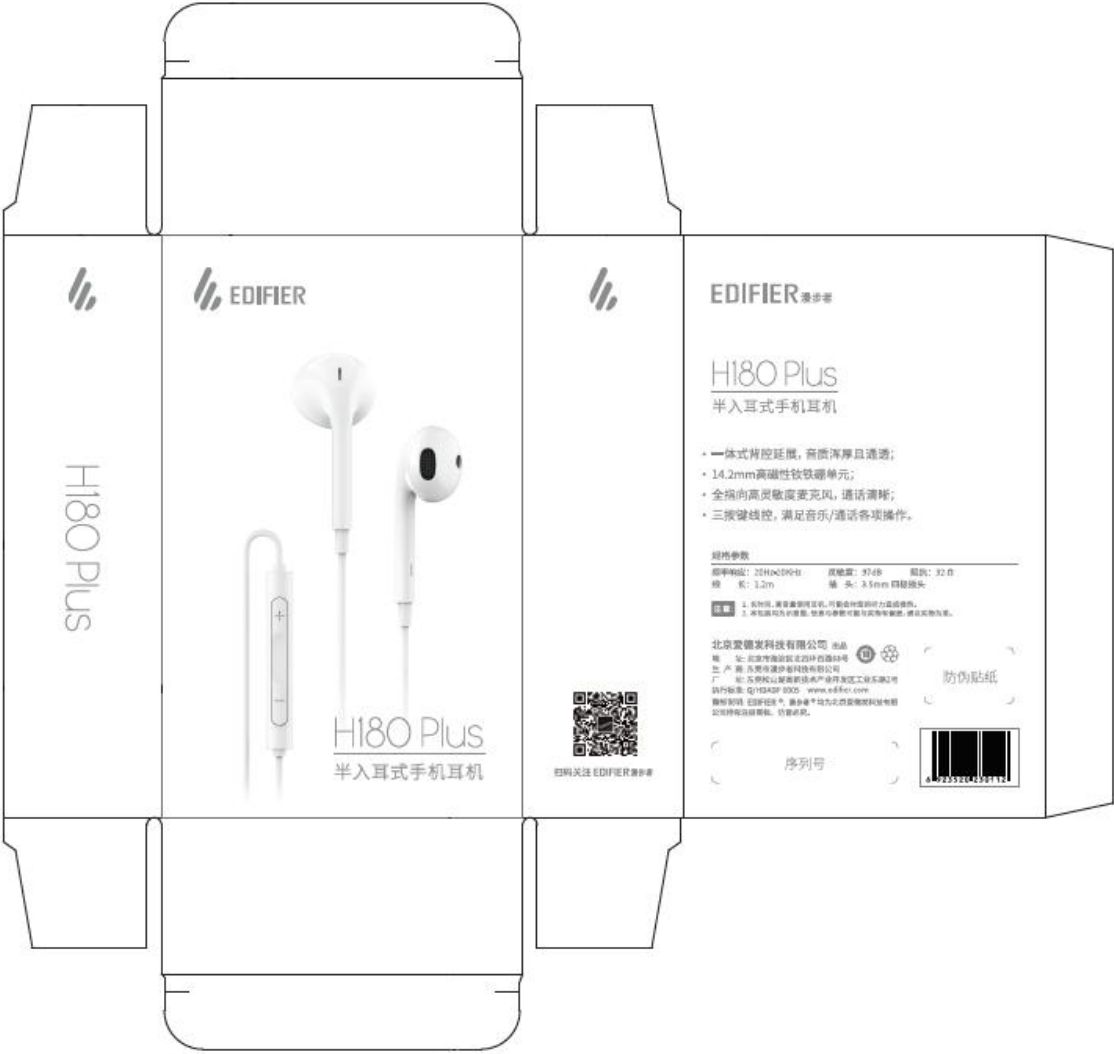

**The domestic package(Chinese version) shown above is for reference only and the finalized package will be in English.*