


GALA-56W

5.25" Quick-fit Mechanism, Metal-Frame Ceiling Speaker

GALA Series offers elegant, reliable and versatile loudspeakers with woofer diameters ranging from 5" to 8", and powers from 3W to 15W RMS. They can be used with standard 70/100V professional amplifiers, and are suitable for any application of music distribution in shops, restaurants, bars, offices, shopping malls, schools, etc.

All GALA speakers feature metal frames and grilles, and quick-fit mechanism, to make installation very easy and fast. The built-in line transformers allow the use with 70/100V lines, and offer two power taps to better adapt to different speaker arrangement and amplifier powers. They come in white color, but can be painted in any color.

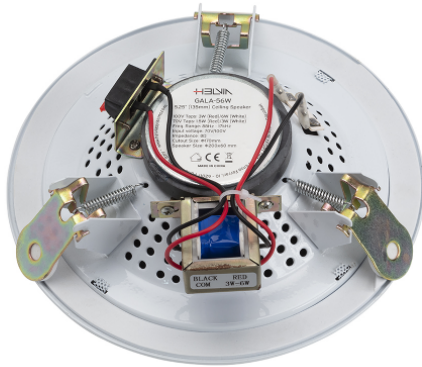

PRODUCT DETAILS

Key features

Full-Range Loudspeaker

Metal-Frame Housing

5.25" Woofer

10W @ 8ohm RMS Power

Built-in 70/100V Line Transformer with 2 powers

Quick-Fit Mechanism

Paintable Grille and Frame

Specifications

Line Voltage	70V/100V
Line Transformer	Built-in, 2 power taps
RMS Power @ 8ohm	10W
100W Power Taps	3W/6W
70V Power Taps	1.5W/3W
Frequency Response (-10dB)	88Hz-17kHz
Sensitivity (1W@1m)	86dB
Impedance	8ohm
Woofer	5.25" (135mm), paper cone
Housing / Grille	Metal, Paintable
IP Rate (speaker installed)	IP42
Mounting	Quick Fit system
Color	White
Cutout Size	Ø 170 mm
Product Size (WxDxH)	Ø 200*60 mm
Speaker Weight	0,8 kg
Packing Size (WxDxH)	200 x 60 x 200 mm
Packing Weight	0,9 kg