



412B.10 | 412 - Cable cutters



Description:

- 412B.10 "Compact" cable cutters: - Capacity: diameter 10 mm. - Integral opening spring. - Lock closed catch. - Cross proof design.
- 412.16 "Standard" cable cutters: - Capacity: diameter 16 mm. - Heavy-duty head, cross proof design. - Safety stop.
- 412.30 - 412.42 "Heavy-duty" cable cutters: - Capacity: 32 mm (Ref. 412.30) and 42 mm (Ref. 412.42).
- Powerful action, cuts without crushing electric cables..
- Safety stop.
- Set of blades for 412.30: 412.L30.
- Set of blades for 412.42: 412.L42.

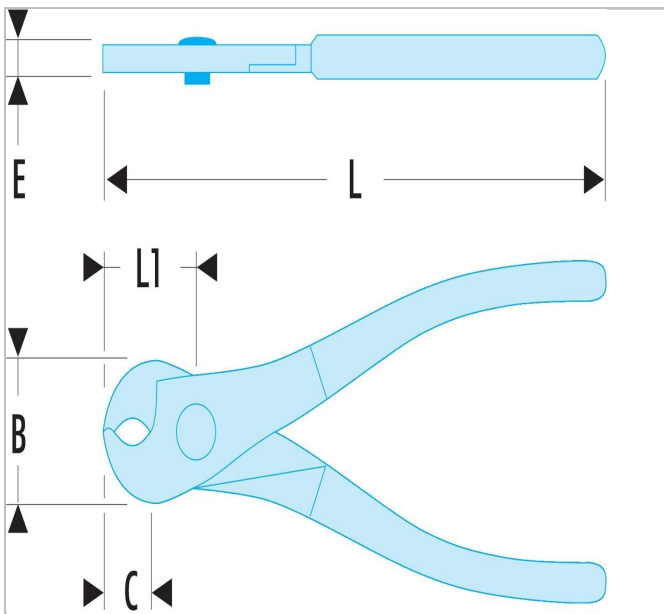

	412B.10
Diameter [mm]	10.0
Diameter D Mini - Maxi [mm]	53 - 190
Length L [mm]	170.0
Length L1 [mm]	40.0
Thickness E [mm]	10.0
Head Height C [mm]	21.0
Head Width B [mm]	28.0
Weight [Kg]	0.225