



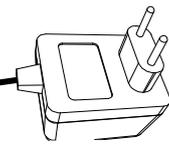

1s - 60 hour start-stop timer module

VM141

Buffered remote pushbutton inputs

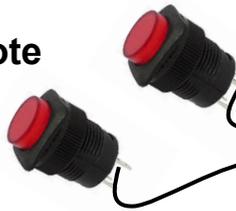


12VDC/100mA

START-button

STOP-button

Timing indicator leds

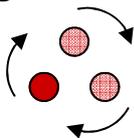

Range select:

- 1.. 6s
- 1.. 60s
- 1.. 60 min
- 1.. 60 hours

Features & specifications:

- Wide timing range
- Easy time setting
- Led animation during operation
- On-board START-STOP buttons
- Non retriggerable
- Power-on trigger is possible
- Debounced buffered inputs avoid false triggering
- Compact size
- Front panel mountable
- Adjustable delay: 1s - 60h
- Power supply: 12VDC / 100mA
- NO/NC relay: 24VAC/DC 3A max.
- Dimensions: 70x45x20mm

Time adjust



Relay output
3A max.

