



This 8.8W retro-fit Integral LED Classic Globe (GLS) (large screw base) delivers a dimmable, warm light and brightness, similar to a 60W filament bulb. It features high output, multi Everlight LEDs, an anti-glare refractor, all finished in an aluminium and plastic, thermally efficient body. Ideal for living rooms, hallways and kitchens.

Details

| | |
|--------------------------|---------------------------------------|
| Barcode: | 5055788238119 |
| Category: | Lamps |
| Range Name: | Everyday |
| Product Type: | GLS |
| Market Segment: | Commercial indoor, Residential indoor |
| Warranty (Years): | 3 |
| CE RoHS: | Yes |

Physical Data

| | |
|---------------------------------|---|
| Product Length (mm): | 120 |
| Product Width (mm): | 60 |
| Product Weight (g): | 100 |
| Material: | Plastic, Aluminium, Nickel plated brass |
| Base Term: | Edison screw |
| Bulb Base: | E27 |
| Construction: | Plastic and Aluminium heat-sink, Polycarbonate diffuser |
| Globe Finish: | Frosted |
| Globe Type: | GLS |
| Bulb Fixing: | Pendant, Wall |
| Bulb or Luminaire Shape: | Round |
| Placement / Application: | Indoor, General Lighting |

Electrical Data

| | |
|--------------------------------|----------|
| Power (W): | 8.8 |
| Power Consumption (w): | 8.8 |
| Power Factor: | 0.8 |
| Wattage equivalent (W): | 60 |
| Amperage (mA): | 52 |
| Dimming: | Dimmable |


| | |
|--------------------------------|-------------------------|
| Driver IC Manufacturer: | Power Integrations (PI) |
| Driver Included: | Yes |
| Electric Current: | AC |
| EN: | EN-62560 |
| LVD Certified: | Yes |

Light Data

| | |
|---|------------------------------|
| Luminous Flux in Lumens (lm): | 806 |
| Luminous efficacy (lm/W): | 92 |
| Lumens Range: | 470 to 850 |
| Correlated Colour Temperature (CCT) (K): | 2700 |
| Colour Temperature: | 2700K - Warm |
| Colour Temperature Name: | Warm |
| Beam Angle: | 220 |
| Colour Rendering Index (CRI): | 80 |
| Frequency Range (Hz): | 50 |
| Instant on (Less than 1 second): | Yes |
| LED Type: | Surface mounted device (SMD) |
| Lifetime (hours): | 25000 |
| Switching Cycles: | 12500 |

Environment

| | |
|--|----------|
| EN: | EN-62560 |
| LVD Certified: | Yes |
| CE RoHS: | Yes |
| Energy Rating: | A+ |
| Hg 0% (Mercury Free): | Yes |
| IP Rating (Ingress Protection): | IP20 |
| Lowest Operating Temperature (°C): | -20 |
| Maximum Operating Temperature (°C): | 40 |

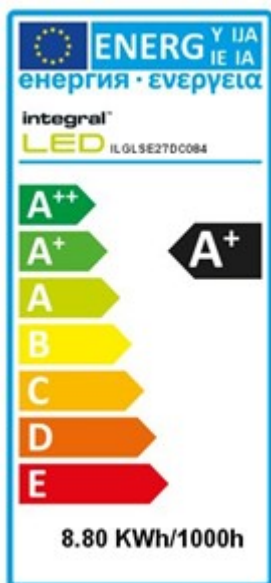

Packaging

| | |
|-----------------------------|-----|
| Package Weight (g): | 140 |
| Package Length (mm): | 135 |

Portal.integral-led.com

| | |
|----------------------------|----|
| Package Width (mm): | 71 |
| Package Depth (mm): | 71 |