



# CorePro LEDcandle



## CorePro LEDcandle ND 7-60W E14 827 B38 FR

The frosted CorePro LEDcandle is designed for retrofit replacement of incandescent lamps. It is compatible with fixtures with an E14 holder and is an attractive product for chandeliers. LEDlamps deliver huge energy savings and minimize maintenance cost.

### Product data


General Information		Power factor (nom.)	
Cap base	E14 [ E14]		0.51
EU RoHS compliant	Yes	Voltage (Nom)	220-240 V
Nominal lifetime (nom.)	15000 h	<b>Temperature</b>	
Switching cycle	50,000X	T-Case maximum (nom.)	87 °C
<b>Light Technical</b>		<b>Controls and Dimming</b>	
Colour Code	827 [ CCT of 2,700 K]	Dimmable	No
Luminous flux (nom.)	806 lm	<b>Mechanical and Housing</b>	
Colour designation	Warm white (WW)	Lamp Finish	Frosted
Correlated Colour Temperature (Nom)	2700 K	Bulb shape	B38
Luminous efficacy (rated) (nom.)	115.00 lm/W	<b>Approval and Application</b>	
Colour consistency	<6	Energy Efficiency Class	E
Colour rendering index (nom.)	80	Energy consumption kWh/1,000 hours	7 kWh
LLMF at end of nominal lifetime (nom.)	70 %		453210
<b>Operating and Electrical</b>		<b>Product Data</b>	
Input frequency	50 to 60 Hz	Full product code	871951431296800
Power (Rated) (Nom)	7 W	Order product name	CorePro LEDcandle ND 7-60W E14 827 B38 FR
Lamp current (nom.)	59 mA	EAN/UPC – product	8719514312968
Wattage equivalent	60 W	Order code	31296800
Starting time (nom.)	0.5 s		
Warm-up time to 60% light (nom.)	0.5 s		

# CorePro LEDcandle

SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929002972502

SAP net weight (piece)	0.053 kg
------------------------	----------


## Dimensional drawing

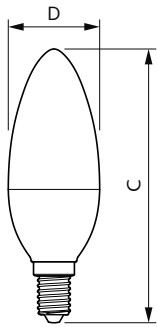


Candle B38 7-60W 806lm 2700K E14 ND FR

Product	D	C
CorePro LEDcandle ND 7-60W E14 827 B38 FR	38 mm	114 mm


## Photometric data

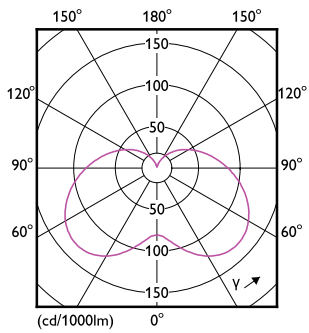

LEDcandle CorePro B38 7W E14 827 FR-LDD

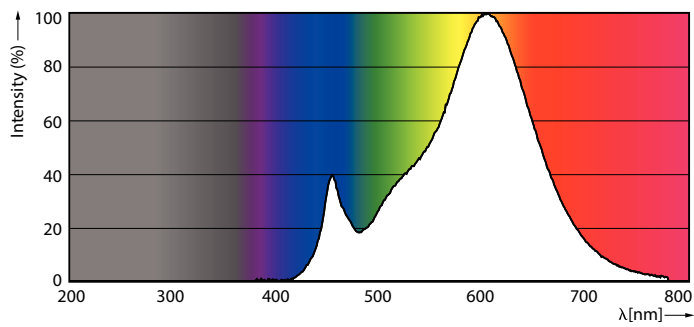

LEDcandle CorePro 7W B38 E14 827 FR-POC

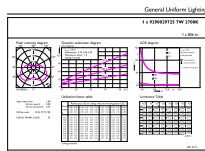

General Uniform Lighting  
1.5m diameter for 2.5m height

LEDcandle CorePro 7W B38 E14 827-GUL

# CorePro LEDcandle

## Lifetime



15K LED

15K LMP

