



# MASTER Glass LED bulbs

## MAS LEDBulb DT7.2-75W E27 927 A60 FR G

Featuring a classic heritage design, classic filament LED lamps combine the familiar shapes of incandescent bulbs with the benefits of the long-lasting LED technology. It is an ideal product to provide customers with a cosy atmosphere. The MASTER LED bulbs can be dimmed to different lumen levels and colour temperatures. MASTER Glass Led Bulbs deliver significant energy savings, offering even 30% more compared to normal LED. They provide excellent quality of light. By offering a lifetime of 25,000 hours, the lamps reduce maintenance costs.

### Product data


General Information		Operating and Electrical	
Cap base	E27 [ E27]	Input frequency	50 to 60 Hz
EU RoHS compliant	Yes	Power (Rated) (Nom)	7.2 W
Nominal lifetime (nom.)	25000 h	Lamp current (nom.)	49 mA
Switching cycle	20,000X	Wattage equivalent	75 W
	Sphere	Starting time (nom.)	0.5 s
		Warm-up time to 60% light (nom.)	0.5 s
		Power factor (nom.)	0.6
		Voltage (Nom)	220-240 V
Light Technical		Temperature	
Colour Code	922-927 [ CCT of 2,200 K-2,700 K]	T-Case maximum (nom.)	70 °C
Luminous flux (nom.)	1055 lm		
Colour designation	Warm Glow (WG)	Controls and Dimming	
Correlated Colour Temperature (Nom)	2200 2700 K	Dimmable	Only with specific dimmers
Luminous efficacy (rated) (nom.)	146.00 lm/W		
Colour consistency	<6	Mechanical and Housing	
Colour rendering index (nom.)	90	Lamp Finish	Frosted
LLMF at end of nominal lifetime (nom.)	70 %		

# MASTER Glass LED bulbs

Bulb shape	A60 [ A 60mm]
<b>Approval and Application</b>	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	8 kWh
	453256
<b>Product Data</b>	
Full product code	871951432493000

Order product name	MAS LEDBulb DT7.2-75W E27 927 A60 FR G
EAN/UPC – product	8719514324930
Order code	32493000
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929003011302
SAP net weight (piece)	0.030 kg


## Dimensional drawing

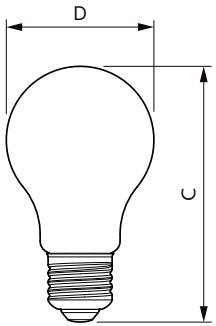


MAS LEDBulb DT7.2-75W E27 927 A60 FR G

Product	D	C
MAS LEDBulb DT7.2-75W E27 927 A60 FR G	60 mm	104 mm

## Photometric data

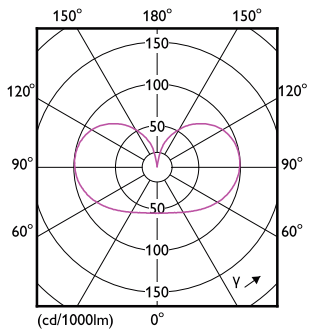

LEDbulb MAS SLR A60 7,2W E27 927 FR-LDD

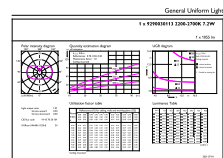


OSRAM Powerline SLR Philips Lighting BV Page 1/1

LEDbulb MAS SLR 7,2W A60 E27 927 FR-GUL

# MASTER Glass LED bulbs

## Photometric data

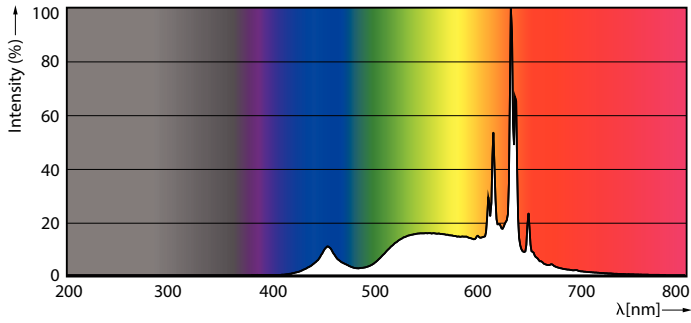

LEDbulb MAS SLR 7,2W A60 E27 927 CL-POC

## Lifetime



LEDspots LED 25K



LEDspots LMP 25K

