



CorePro GLASS LED candles and lustres

CorePro LEDLuster ND 2.2-25W P45 E27 FRG

Featuring a classic heritage design, Classic filament LED lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lustres: compared to convential lamps, it provides a 90% energy saving. CorePro Glass LED candles and lustres provide excellent quality of light. By offering a lifetime of 15,000 hours, they reduce maintenance costs.

Product data

General Information	
Cap base	E27 [E27]
EU RoHS compliant	Yes
Nominal lifetime (nom.)	15000 h
Switching cycle	20,000X
	Sphere

Light Technical	
Colour Code	827 [CCT of 2,700 K]
Luminous flux (nom.)	250 lm
Colour designation	Warm white (WW)
Correlated Colour Temperature (Nom)	2700 K
Luminous efficacy (rated) (nom.)	113.00 lm/W
Colour consistency	<6
Colour rendering index (nom.)	80
LLMF at end of nominal lifetime (nom.)	70 %

Operating and Electrical	
Input frequency	50 to 60 Hz

Power (Rated) (Nom)	2.2 W
Lamp current (nom.)	21 mA
Wattage equivalent	25 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light (nom.)	0.5 s
Power factor (nom.)	0.4
Voltage (Nom)	220-240 V

Temperature	
T-Case maximum (nom.)	36 °C

Controls and Dimming	
Dimmable	No

Mechanical and Housing	
Lamp Finish	Frosted
Bulb shape	P45 [P 45mm]

CorePro GLASS LED candles and lustres

Approval and Application


Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	3 kWh
	387385

Product Data

Full product code	871951434683300
Order product name	CorePro LEDLuster ND 2.2-25W P45 E27 FRG

EAN/UPC – product	8719514346833
Order code	34683300
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929001345692
SAP net weight (piece)	0.012 kg


Dimensional drawing

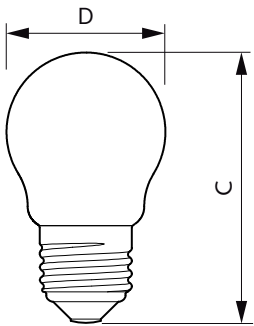


CorePro LEDLuster ND 2.2-25W P45 E27 FRG

Product	D	C
CorePro LEDLuster ND 2.2-25W P45 E27 FRG	45 mm	78 mm

 
Photometric data



LEDbulb, Bulb A21 14W, 18W 2200-2700K

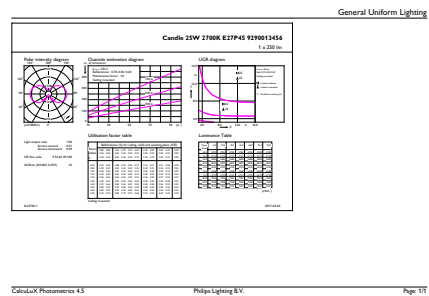


LEDbulb 25W E27 827 FR P45

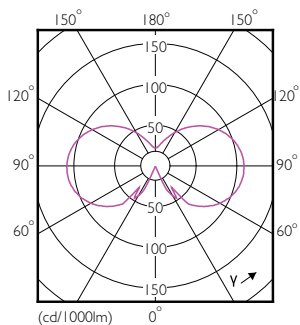


LEDbulb 25W E14 827 FR B35

CorePro GLASS LED candles and lustres

Lifetime

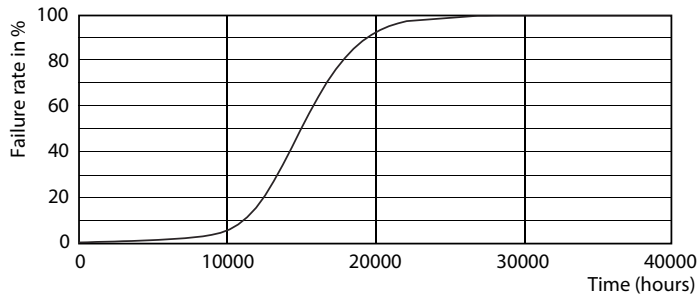

LEDbulb 25W E14 827 FR B35

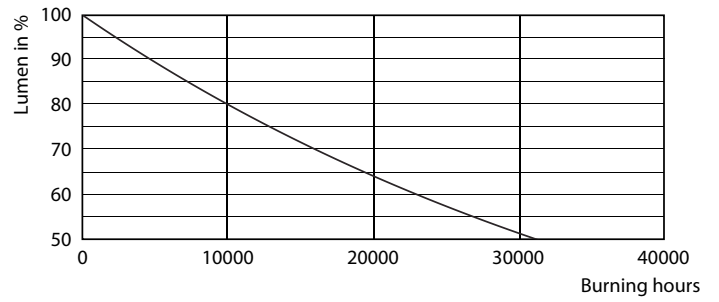

LEDbulb 25W E14 827 FR B35

