



Technical Hotline
+44 (0)1268 563720

Boxes

PVC Boxes

19MM
SURFACE



2120WHI 10
FOR 1, 2 AND 3 GANG
PLATESWITCHES

With earth terminal
DIMENSIONS
87 x 87mm
FIXING CENTRES
60.3mm

Knockouts 'cut-out' provided in top and bottom for 16mm oval PVC conduit. 20mm round 'push-out' type knockout in base for cable entry. Fixing holes are also provided for mounting to wall or over BS 4568-2 small circular boxes.
BS 5733:2010

32MM
SURFACE



2180WHI 10
1 GANG
2181WHI 10
1 GANG

DIMENSIONS
87 x 87mm
FIXING CENTRES
60.3mm


KNOCKOUTS
2180: One 'push-out' for 20mm oval conduit in top, one 'cut-out' for 20mm or 25mm oval conduit and one 20mm round 'push-out' in the base.
2181: One 'push-out' for 20mm round conduit in top and one 20mm round 'push-out' in base.
BS 5733:2010



2182WHI 5
2 GANG
2183WHI 5
2 GANG

DIMENSIONS
87 x 148mm
FIXING CENTRES
120.6mm

KNOCKOUTS
2182: Two 'push-outs' for 20mm oval conduit in top, two 'cut-outs' for 20mm or 25mm oval conduit and one 20mm round 'push-out' in base
2183: One 'push-out' for 20mm round conduit in top and one 20mm round 'push-out' in base.
BS 5733:2010

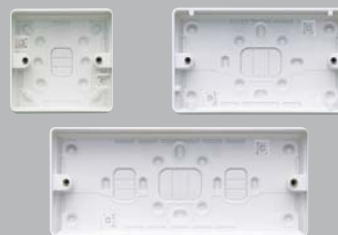

K2181WHI 10
FOR 1 GANG LOGIC PLUS™ POWER ACCESSORIES
K2183WHI 5
FOR 2 GANG LOGIC PLUS™ POWER ACCESSORIES
K2185WHI 5
FOR 3 GANG LOGIC PLUS™ POWER ACCESSORIES

KNOCKOUTS

K2181: One 'cut-out' for 20mm round conduit in top face, one 'cut-out' for 20mm or 25mm oval conduit in lower face and one 20mm round 'push-out' in the base.

K2183 and K2185: One 'cut-out' for 20mm round conduit in top face, two 'cut-outs' for 20mm or 25mm oval conduit in lower face and one 20mm round 'push-out' in the base. Both boxes are suitable for fitting over 1 gang and 2 gang BS 4662 flush steel boxes respectively.

DIMENSIONS

1 gang: 87 x 87mm
2 gang: 87 x 148mm
3 gang: 87 x 208mm

FIXING CENTRES

1 gang: 60.3mm
2 gang: 120.6mm
3 gang: 180.9mm
BS 4662:2006 where applicable

Moulded Boxes

ARCHITRAVE
SURFACE



K2151WHI 10
1 GANG
ARCHITRAVE BOX
K2152WHI 5
2 GANG
ARCHITRAVE BOX

Earth terminal fitted in base of boxes.

DIMENSIONS
1 gang: 87 x 33 x 16mm
2 gang: 148 x 33 x 16mm
FIXING CENTRES
1 gang: 60.3mm
2 gang: 120.6mm
BS 5733:2010

16MM
SURFACE




K2160WHI 10
FOR 1, 2 AND 3 GANG LOGIC PLUS™ PLATESWITCHES
K2161WHI 5
FOR 4 AND 6 GANG LOGIC PLUS™ PLATESWITCHES

Earth terminal fitted in base of boxes. Knockouts provided in sides and bases.

DIMENSIONS
1 gang: 87 x 87mm
2 gang: 87 x 148mm
FIXING CENTRES
1 gang: 60.3mm
2 gang: 120.6mm
BS 5733:2010

30MM
SURFACE

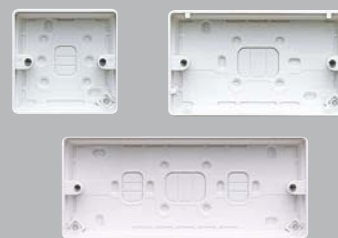

K2140WHI 10
FOR 1 GANG LOGIC PLUS™ POWER ACCESSORIES
K2142WHI 5
FOR 2 GANG LOGIC PLUS™ POWER ACCESSORIES
K2153WHI 5
FOR 3 GANG LOGIC PLUS™ POWER ACCESSORIES

Knockouts in base and sides for cable entry
K2142 and K2153 are suitable for fitting over 1 gang and 2 gang BS 4662 flush steel boxes respectively

DIMENSIONS
1 gang: 87 x 87mm
2 gang: 87 x 148mm
3 gang: 87 x 208mm
FIXING CENTRES
1 gang: 60.3mm
2 gang: 120.6mm
3 gang: 180.9mm
BS 5733:2010