


# ONYX Lamp

A high-powered LED professional lamp, which is designed to light up wide areas on a desk, workstation, drawing board or large painting.

Featuring a large shade, which can be smoothly adjusted vertically, horizontally and laterally to any desired position, ensuring that daylight is where it is needed most.

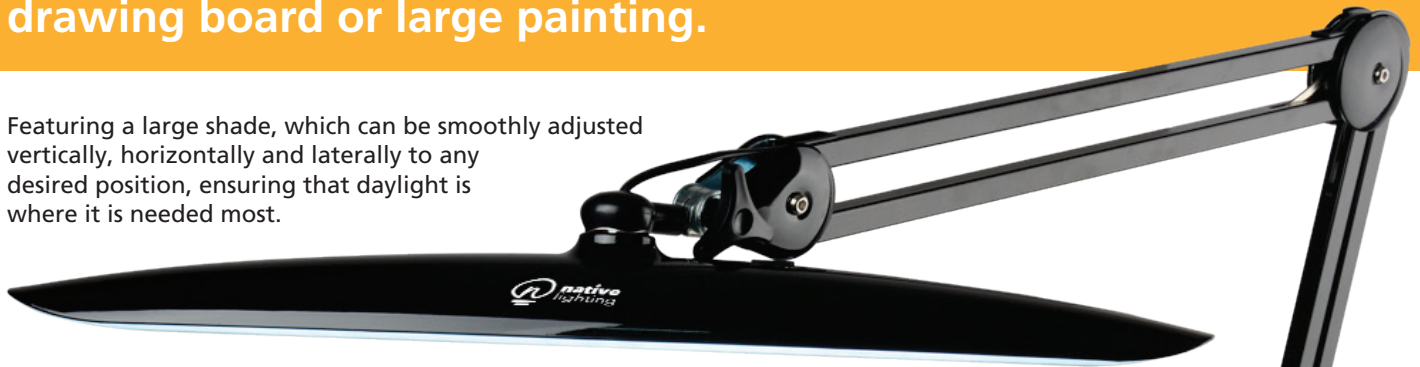

The durable metal arm ensures that the lamp head can be positioned at the users desired height.

## FEATURES

- Wide head ensures light spreads evenly across large areas.
- Adjustable head means you can shine light exactly where you need it.
- 117 LED's.
- Dimmer - ON 100% - 75% - 50% - 25% - OFF
- Fixes to surfaces via a clamp (which is supplied).
- A long arm reach of 98cm (38.5 inches).

## TECHNICAL DETAILS

- Colour temperature: 6500K (daylight).
- Head width: 50cm (19.75 inches), Head depth: 9.5cm (3.75 inches), Reach: 98cm (38.5 inches), Clamp depth: 6.2cm (2.5 inches).
- Weight: 1.68kg.
- Colour: Black.
- Comes with a 2 year warranty.



Wide illumination



Dimmer Function



Clamp fixing



Colour temp 6500K

Telephone 0117 370 9995 Email [sales@native-lighting.com](mailto:sales@native-lighting.com)  
For more information visit [www.native-lighting.com](http://www.native-lighting.com)