

# Slim Portable 8X DVD Writer

SDRW-08D2S-U LITE

ASUS SDRW-08D2S-U LITE is a portable 8X DVD writer that provides an easy burning solution in a lightweight and stylish package. For data backup, this drive is M-DISC support that allows you to preserve your priceless data for a millennium. More, the professional data backup software provides the most robust backup solution.

## FEATURES

### M-DISC Support

*Save users' data for up to 1,000 years*

### Disc Encryption II\*

*Protect users' data with password control and encoded file name functionality*

### Nero BackItUp\*

*Full backup for your Android devices*

### PowerBackup\*

*Professional PC backup software*



## SPECIFICATIONS

### Color

Black/White

### Read Speed

DVD±R: 8X  
DVD+R(SL, M-DISC): 8X  
DVD±RW: 8X  
DVD-ROM: 8X  
DVD±R(DL): 8X  
DVD-ROM(DL): 8X  
CD-R/ROM/RW: 24X  
DVD-Video Playback: 4X  
Audio CD Playback: 10X

### Write Speed

DVD±R: 8X  
DVD+R(SL, M-DISC): 4X  
DVD±RW: 8X  
DVD-RW: 6X  
DVD±R(DL): 6X  
CD-R/RW: 24X

### Access Time (Random)

DVD: 170 ms  
CD: 160 ms

### O/S Compatibility

Windows® 10  
Windows® 8.1  
Mac OS® X 10.6 and above

### Bundled Software (For Windows OS)

CyberLink Power2Go 8  
CyberLink PowerBackup 2.6  
Nero BackItUp  
E-Green

### Writing Mode

- (1) DVD-R: Disc at Once and Incremental Recording
- (2) DVD-R DL: Disc at Once and Incremental Recording
- (3) DVD-RW: Disc at Once, Incremental Recording and Restricted Overwriting
- (4) DVD+R: Sequential Recording
- (5) DVD+R DL: Sequential Recording
- (6) DVD+RW: Random Recording
- (7) CD-R/RW: Disc at Once, Session at Once, Track at Once and Packet Recording

### System Requirement

CPU: Intel® Pentium® 4 2.0 GHz or AMD Athlon™ 2100+ or higher  
RAM: 512 MB or more is recommended  
HDD: 10 GB or more

### Disc Formats

#### Reading:

DVD±R(SL/DL), DVD±RW, DVD-ROM(SL/DL), DVD-Video, CD-R, CD-RW, CD-ROM, Audio CD, VCD, CD-I, CD-Extra, Photo CD, CD-text, CD-ROM/XA, Multi-session CD

#### Writing:

DVD±R(SL/DL), DVD±RW, CD-R, CD-RW

## Configurations

### Dimensions

142 x 142 x 20 mm (L/W/H)

### Weight

250 ± 20 g

### Interface

USB 2.0 (Type-A)

### Disc Diameters

12 cm and 8 cm

## Electrical and Environmental Specifications

### Power Requirement

USB Power +5V ± 5%

### Temperature

Operating: 5° C to 40° C  
Storage: -30° C to 60° C

### Humidity

Operating: 15%~80% (Non-condensing)  
Storage: 10%~90% (Non-condensing)

\*This feature is for Windows OS only

# Package Contents



Optical Drive



QIG  
(Quick Installation Guide)



Software



USB Y Cable



## M-DISC Support

*1000-year Storage Solution*

Save your priceless memories or data for up to 1,000 years.



1 / burn your data with M-DISC

2 / engrave on a rock-like layer


3 / store for up to 1,000 years



## Disc Encryption II\*

*Double Security On-the-Go*

Password control access and hidden-file folder function.

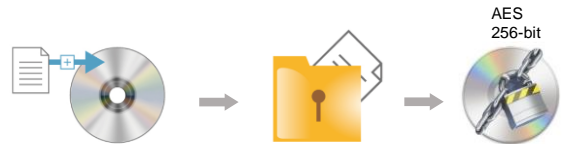

1 / copy the file

2 / password setting folder hidden

3 / encryption

\*This feature is for Windows OS only



## Nero BackItUp\*

*Full Backup for Your Android Devices*

Free included app makes it easy to back up all of your important data to the hard drive or SD card on the PC wirelessly.



1 / install the software

2 / choose destination

3 / backup

\*This feature is for Windows OS only



## Drag and Burn\*

*3 Easy Steps to Complete Disc Burning*

Intuitive burning interface in only 3 simple steps to burn a disc.



1 / drag & drop to the thumbnail

2 / burn

3 / done


\*This feature is for Windows OS only



## PowerBackup\*

*Professional Backup Software*

With auto backup scheduler and data archiving application, PowerBackup provides the most robust data backup solution.

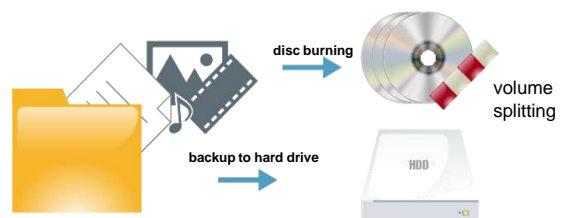

\*This feature is for Windows OS only

massive data

auto backup