



Mitutoyo

Digital Indicator ID-C Item number: 543-391B

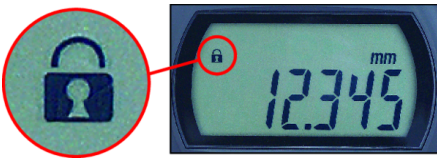

Images

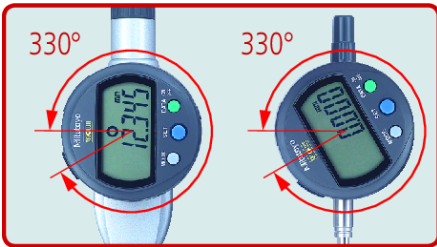


Description

A Mitutoyo digital indicator of similar size to a Series 2 type dial indicator. ABSOLUTE System scale for error free, high-speed measurement. Functionality includes displaying the result of an internal calculation based on spindle displacement, according to a single-term user-defined formula (Ax), and tolerance judgement. SPC data output.

Specification

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
No. Lug back plate:	543-391
Range:	0.5"/12.7 mm
Range:	0,5" Inch
Digital step:	0,00005"/0,001 mm
Hysteresis:	0,0001"/0,002 mm
H MPE (Hysteresis):	0,0001"/0,002 mm mm
R MPE (Repeatability):	0,0001"/0,002 mm
Measuring force:	≤ 1,5 N
Protection:	IP42
Type:	EN ISO Standard
Display:	LCD, character height 11 mm rotatable 330°
Max. response speed:	Unlimited
Alarm:	Low voltage, counting value composition error, overflow error, tolerance limit setting error
Stem Ø:	8 mm
Contact point:	Carbide ball, thread M 2.5 x 0.45 mm
Power supply:	1 battery SR-44
Battery life:	approx. 7000 hours
Delivered:	Including 1 battery
DATA/HOLD:	Yes
PRESET:	Yes
Digimatic data output:	Yes
ON/OFF:	Yes
GO/±NG judgement:	Yes
ABS / INC (INC ZERO):	Yes
Selectable resolution:	Yes
Calculation function (with formula):	Yes
Counting direction switchable:	Yes
Mass:	170 g

Dimensions

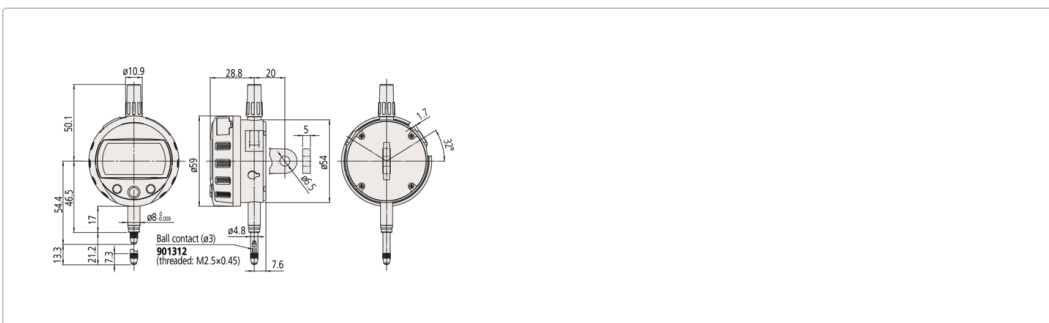

Accessories

Optional accessories: