



HOOP

GU10 STEEL DOWNLIGHT

Hoop delivers outstanding value for money for a GU10 downlight. Featuring steel bezels and available in Fixed and Tilt options in 4 colour finishes.



Features


- Value for money GU10 downlight
- Fixed & Tilt options available
- Choice of white, chrome, satin chrome and brass finish
- Supplied with pre-wired lampholder and terminal block mounting bracket
- Recommended for use with Red Arrow GU10 LED lamps (order separately)



Specification

Material:	Bezel: Steel
IP Rating:	IP20
Electrical Class:	Class I
Guarantee:	1 Year

Dimensions

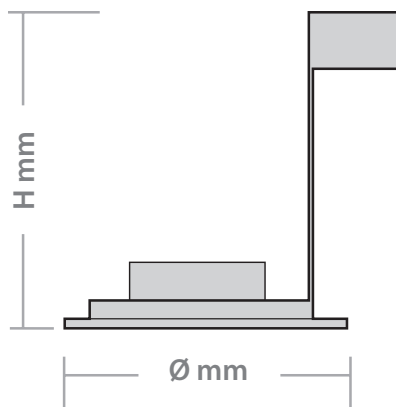

Product	Dimensions	Cut Out
Fixed	H: 100mm, Ø: 80mm	Ø57mm
Tilt	H: 95mm, Ø: 88mm	Ø67mm

Product Code	Description	Colour Finish	Weight (Kg)	Barcode
HS/FW	Hoop Fixed	White	0.09	5055807621700
HS/FC	Hoop Fixed	Chrome	0.09	5055807621717
HS/FSC	Hoop Fixed	Satin Chrome	0.09	5055807621724
HS/FB	Hoop Fixed	Brass	0.09	5055807621731
HS/TW	Hoop Tilt	White	0.14	5055807621748
HS/TC	Hoop Tilt	Chrome	0.14	5055807621755
HS/TSC	Hoop Tilt	Satin Chrome	0.14	5055807621762
HS/TB	Hoop Tilt	Brass	0.14	5055807621779



Satin Chrome Finish Tilt



Brass Finish Fixed



Satin Chrome Finish Fixed



www.redarrowelectrical.co.uk

