



IGNIS PLUS

GU10 DIE-CAST FIRE RATED DOWNLIGHT

Ignis Plus is a range of high quality, fire rated die-cast aluminium downlights. Designed for use with GU10 lamps, the range is available as Fixed, Tilt and IP65 options and features an innovative fast-fit, tool-less terminal block.



Features


- Fire rated for 30, 60 & 90 minutes to BS 476:20:1987 & BS476:21:1987
- Acoustic rating: ISO 10140-2:2010
- IP65, Fixed & Tilt options available
- White, chrome, satin chrome and brass finish
- Includes terminal block with heavy duty loop-in / loop-out lever terminals
- Recommended for use with Red Arrow GU10 LED lamps (order separately)



Specification

| | |
|--------------------------|---|
| Material: | Bezel: Die-Cast Aluminium Housing: Steel |
| IP Rating: | IP20 / IP65 (IP65 from below ceiling) |
| Electrical Class: | Class: I |
| Guarantee: | 1 Year |

Dimensions

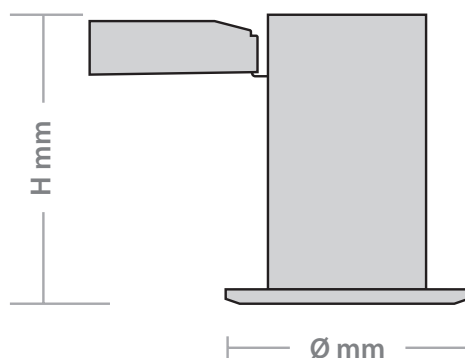

| Product | Dimensions | Cut Out |
|--------------|-------------------|---------|
| Fixed | H: 95mm, Ø: 86mm | Ø75mm |
| Tilt | H: 95mm, Ø: 100mm | Ø90mm |
| IP65 | H: 105mm, Ø: 86mm | Ø75mm |


| Product Code | Description | Colour Finish | IP Rating | Weight (Kg) | Barcode |
|--------------|------------------|---------------|-----------|-------------|---------------|
| IGP/FW | Ignis Plus Fixed | White | IP20 | 0.26 | 5055807621380 |
| IGP/FC | Ignis Plus Fixed | Chrome | IP20 | 0.26 | 5055807621397 |
| IGP/FSC | Ignis Plus Fixed | Satin Chrome | IP20 | 0.26 | 5055807621403 |
| IGP/FB | Ignis Plus Fixed | Brass | IP20 | 0.26 | 5055807621410 |
| IGP/TW | Ignis Plus Tilt | White | IP20 | 0.36 | 5055807621427 |
| IGP/TC | Ignis Plus Tilt | Chrome | IP20 | 0.36 | 5055807621434 |
| IGP/TSC | Ignis Plus Tilt | Satin Chrome | IP20 | 0.36 | 5055807621441 |
| IGP/TB | Ignis Plus Tilt | Brass | IP20 | 0.36 | 5055807621458 |
| IGP/65W | Ignis Plus IP65 | White | IP65 | 0.36 | 5055807621465 |
| IGP/65C | Ignis Plus IP65 | Chrome | IP65 | 0.36 | 5055807621472 |
| IGP/65SC | Ignis Plus IP65 | Satin Chrome | IP65 | 0.36 | 5055807621489 |
| IGP/65B | Ignis Plus IP65 | Brass | IP65 | 0.36 | 5055807621496 |



Brass Finish IP65



Chrome Finish Tilt

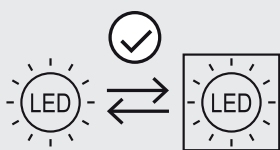

www.redarrowelectrical.co.uk