



# IGNIS


## GU10 STEEL FIRE RATED DOWNLIGHT

Offering excellent value for money, Ignis is a range of fire rated downlights with steel bezels. Designed for use with GU10 lamps, as Fixed and Tilt options in 4 finishes. All feature Red Arrow's innovative terminal block.



### Features


- Fire rated for 30, 60 & 90 minutes to BS 476:20:1987 & BS476:21:1987
- Acoustic rating: ISO 10140-2:2010
- Fixed & Tilt options available
- White, chrome, satin chrome and brass finish
- Includes fast-fit terminal block with heavy duty loop-in / loop-out lever terminals
- Recommended for use with Red Arrow GU10 LED lamps (order separately)

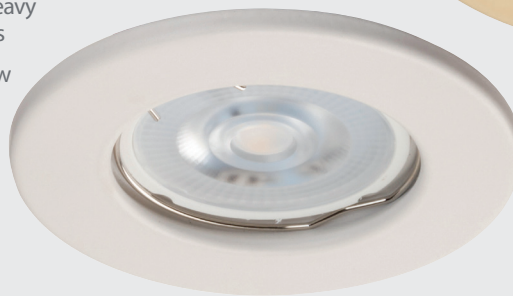

### Specification

<b>Material:</b>	Bezel & Housing: Steel
<b>IP Rating:</b>	IP20
<b>Electrical Class:</b>	Class I
<b>Guarantee:</b>	1 Year

### Dimensions

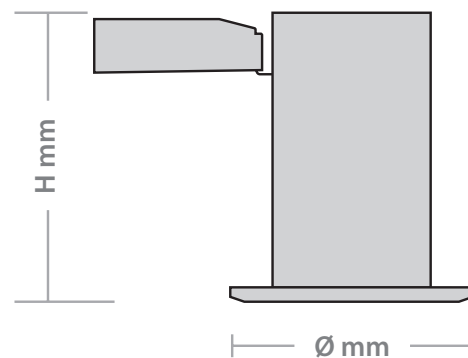

Product	Dimensions	Cut Out
<b>Fixed</b>	H: 85mm, Ø: 85mm	Ø65mm
<b>Tilt</b>	H: 95mm, Ø: 87mm	Ø75mm


Product Code	Description	Colour Finish	Weight (Kg)	Barcode
IGS/FW	Ignis Fixed	White	0.26	5055807621502
IGS/FC	Ignis Fixed	Chrome	0.26	5055807621519
IGS/FSC	Ignis Fixed	Satin Chrome	0.26	5055807621526
IGS/FB	Ignis Fixed	Brass	0.26	5055807621533
IGS/TW	Ignis Tilt	White	0.26	5055807621540
IGS/TC	Ignis Tilt	Chrome	0.26	5055807621557
IGS/TSC	Ignis Tilt	Satin Chrome	0.26	5055807621564
IGS/TB	Ignis Tilt	Brass	0.26	5055807621571



Chrome Finish Fixed



White Finish Tilt

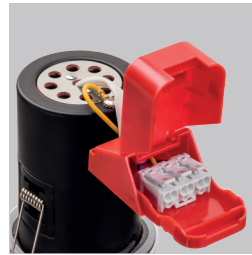

[www.redarrowelectrical.co.uk](http://www.redarrowelectrical.co.uk)

