

5-IN-1

MULTI-POSITIONAL EXIT SIGN



Our 5 in 1 LED Emergency Exit Sign is incredibly versatile and can be mounted in 5 different ways, without any additional accessories. Can be configured for maintained or non-maintained operation.

Features



- Ceiling, wall and 90° flag mounting
- Suspended and recessed mounting kits included
- Choice of legend (supplied separately)
- Latest LiFeP04 battery technology





Specification

Material:	Polycarbonate (Legend - Acrylic)
Colour Temperature:	6000K
Colour Finish:	Green & White
CRI	Ra>70
LED Lifetime:	L70B50 40,000 Hrs
Power Factor:	0.5
Emergency Battery Type:	LifeP04
IP Rating:	IP20
IK Rating:	IK20
Working Temperature:	0°C to 40°C
Electrical Class:	Class II
Guarantee:	2 Years

Dimensions

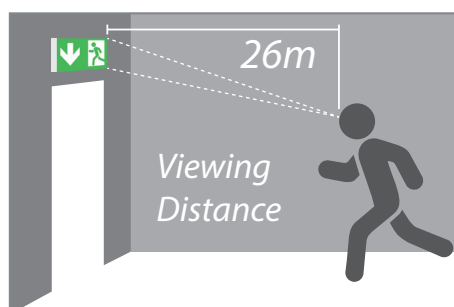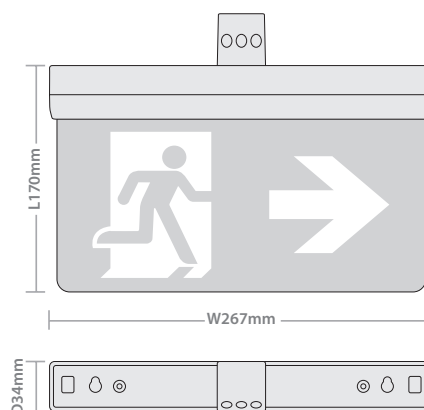

Product Code	Description	Wattage	Lumen Output	Net Weight (kg)	Barcode
MPESPW	5 In 1 Emergency Exit Sign Excluding Legend	1W/2W	60 lm	0.33	5055807620574
MPELUPW	5 In 1 Exit Legend Up	-	-	0.14	5055807620567
MPELDPW	5 In 1 Exit Legend Down	-	-	0.14	5055807620543
MPELLRPW	5 In 1 Exit Legend Right / Left	-	-	0.14	5055807620550

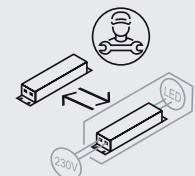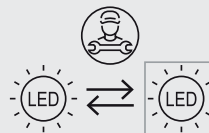

www.redarrowelectrical.co.uk