



# WEATHERGUARD

IP65 NON-CORROSIVE FITTINGS FOR LED TUBES



Weatherguard is our latest and improved IP65 corrosion resistant luminaire designed for use with LED T8 tubes. Now with lockable stainless steel clips as standard.

## Features


- Suitable for use with Red Arrow LED T8 Tubes - to be purchased separately
- Robust IP65 rated housing
- Supplied with stainless steel diffuser clips
- IK07 rated for hard-wearing industrial use



## Specification

<b>Material:</b>	Body & Diffuser: Polycarbonate Retaining Clips: Stainless Steel
<b>IP Rating:</b>	IP65
<b>Colour Finish:</b>	Grey
<b>IK Rating:</b>	IK07
<b>Working Temperature:</b>	-25°C to 40°C
<b>Electrical Class:</b>	Class I
<b>Guarantee:</b>	2 Years

## Dimensions

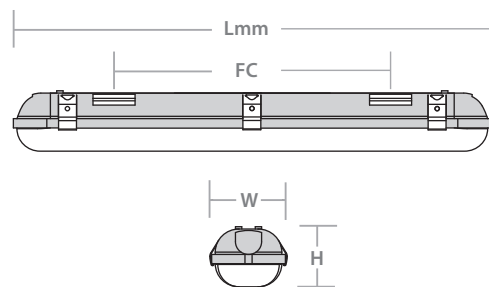

Product Code	Dimensions	Fixing Centres FC
WG21	L: 664 x W: 72 x D: 78mm	400mm
WG22	L: 664 x W: 103 x D: 78mm	400mm
WG41	L: 1262 x W: 72 x D: 78mm	900mm
WG42	L: 1262 x W: 103 x D: 78mm	900mm
WG51	L: 1562 x W: 72 x D: 78mm	1200mm
WG52	L: 1562 x W: 103 x D: 78mm	1200mm

Product Code	Description	Net Weight (kg)	Barcodes
WG21	Weatherguard for 1 x 600mm LED Tube	0.58	5055807621250
WG22	Weatherguard for 2 x 600mm LED Tubes	0.73	5055807621267
WG41	Weatherguard for 1 x 1200mm LED Tube	1.03	5055807621274
WG42	Weatherguard for 2 x 1200mm LED Tubes	1.35	5055807621281
WG51	Weatherguard for 1 x 1500mm LED Tube	1.5	5055807621137
WG52	Weatherguard for 2 x 1500mm LED Tubes	1.16	5055807621144



[www.redarrowelectrical.co.uk](http://www.redarrowelectrical.co.uk)