

# PSI Displays Ltd



Suite C2, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

 

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

## LCD COLOUR MONITOR Model No. L104HM

10.4" TFT LCD Colour Video Monitor with LED Back Light, 1204 x 768, HDMI x 2, DVI, VGA, Composite Video In/Out BNC. Y/C (S-Video), Audio In/Out and via speakers. I/R Remote control. Optional: Glass Front, Touch screen, 19" Rack mounting. Other sizes available.



19" Rack Mount option.

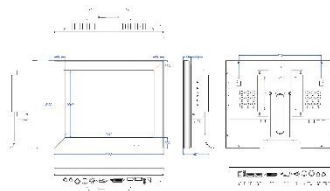

### Main Features:

- Resolution: 1024 x 768
- Picture Ratio: 4:3
- Brightness: 350 cd/m<sup>2</sup> LED Back Light.
- Contrast Ratio: 1000:1
- Inputs: HDMI x 2, DVI, VGA, Composite video, S-Video, Audio.
- Outputs: Composite Video, Audio.
- Mounting: VESA 75 or 100, Key Hole, Stand.
- Aluminium Cabinet finished in Black.
- Speaker: 2 Watts max.
- USB for Media and service use.

The L104HM with TFT technology, offers Professional sharp images and with high contrast ratio 1000:1 and Brightness 350 cd/m<sup>2</sup> gives superb pictures. With 2 x HDMI, DVI, VGA, S-Video, Composite video BNC In/Out, Audio In/Out and via speaker making it a truly versatile Monitor. Mounting options offering VESA 75 + 100 & Key hole mounting and with a Desk stand. Infra-Red remote control. All mounted in a Smart tough Aluminium Metal housing. This compact unit is ideal for Multimedia Video and Surveillance systems applications.

### SPECIFICATIONS:

- Active area: 210.4 x 157.8 (WxH)mm. • 16.7M Colours. • PAL and NTSC Auto.
- Response Time: 14/11ms (Tr/Tf). • Viewing angle: Left/Right: 88°, Up/Down 88°.
- Controls/Indicators: Source, Menu, Item, Up, Down, Power. Front: On LED and I/R sensor.
- Power Source: 12V DC, 0.8 Amp, 10 Watts approx. AC Adaptor: 100-240V 50/60Hz 1.5Amps.
- Dimensions: 266 x 214 x 41 (60 with stand). Carton: 335 x 290 x 110 (WxHxD)mm.
- Weight: Unit: 2.3 Kgms, Carton: 3.10 Kgms. • Temp: Operation: 0~40°C.

**Connections:** HDMI In x 2: Type A socket. DVI: DVI-D socket. VGA: 15 pin Sub-D socket. Composite Video In/Out: BNC socket. Y/C (S-Video) In: 4 pin mini din socket, Audio In/Out 3.5mm Jack sockets. DC input: 2.1mm jack socket. AC adaptor: IEC socket. USB in: Type A socket for Media and service use.

**Standard accessories:** AC adapter, UK AC Mains Lead, I/R Remote Control.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO

# PSI Displays Ltd



Suite C2, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

e-mail: [sales@psidisplays.co.uk](mailto:sales@psidisplays.co.uk) Website [www.psidisplays.co.uk](http://www.psidisplays.co.uk)