

PSI Displays Ltd



 
 


Suite C2, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

LCD COLOUR MONITOR Model No. L215HM

21.5" TFT LCD Full HD Colour Monitor LED Back Light, 1920 x 1080P, inputs of HDMI x 2, DVI, VGA, Composite Video In/Out BNC. Y/C (S-Video), Audio In/Out and via Speakers, I/R Remote Control. **Options:** Touch screen or Glass Front. Other sizes available.

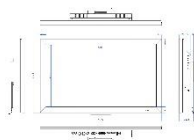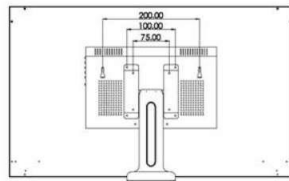

Main Features:

- Resolution: 1920 x 1080P – Full HD
- Picture Ratio: 16:9
- Brightness: 250 cd/m2 - LED Back Light.
- Contrast Ratio: 3000:1
- Inputs: HDMI, DVI, VGA, Composite video BNC. S-Video, Audio.
- Outputs: Composite Video BNC, Audio.
- Mounting: VESA 75 or 100, Key Hole, Stand.
- Slim Aluminium cabinet finished in Black.
- 3D De-Interlaced Technology.
- Anti-blur/image auto.
- Speaker 2 x 2 Watts max.
- USB: For Media and service use.

The L215HM with LED back light and TFT technology offers Professional sharp images and with high contrast ratio 3000:1 and Brightness 250 cd/m2 gives superb pictures. With HDMI, DVI, VGA, S-Video (Y/C) Composite Video In/Out BNC Connectors, Video Loop through, Audio In/Out and Audio via speakers making it a truly versatile Monitor. Mounting options offering VESA 75 + 100 & Key hole mounting and with a Desk lean-to stand. Infra-Red remote control. and all finished in a Smart tough Aluminium Metal housing. This compact unit is ideal for Multimedia Video and Surveillance systems applications.

SPECIFICATIONS:

- Active area: 476.064 x 267.786 (WxH)mm. • 16.7M Colours. • PAL and NTSC Auto.
- Response Time: 13/5 ms (Tr/Tf). • Viewing angle: Left/Right: 89°, Up/ Down 89°.
- Controls/Indicators: Front: On LED, I/R sensor. Rear: Source, Menu, Item, Up, Down, Power.
- Power Source: 12V DC, 1.83 Amp, 21 Watts approx. AC Adaptor: 90-264V 50/60Hz 1.5Amps.
- Dimensions: 532.3 x 323.3 x 56 (65 with stand). Carton: 620 x 500 x 180 (WxHxD)mm.
- Weight: Unit: 4.66 Kgms, Carton: 6.79 Kgms. • Temp: Operation: 0°C~50°C.

Connections: HDMI In x 2: Type A Sockets. DVI: DVI-D socket. VGA: 15 pin Sub-D socket, Composite Video In/Out: BNC. Y/C (S-Video) In: 4 pin mini din socket. Audio In/Out: 3.5mm Jack socket. DC input: 2.1mm socket. AC adaptor: IEC socket. USB In: Type A socket for Media and service use.

Standard accessories: AC adapter, UK AC Mains Lead, I/R Remote Control.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO