

PSI Displays Ltd



 

Suite C2, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

LCD SDI COLOUR MONITOR Model No. L240HMSDI

24.0" TFT LCD SDI Full HD Colour Monitor, 1920 x 1080P, LED Back Light, inputs SDI In/Out, HDMI, DVI, VGA, Composite Video In/Out BNC. Y/C (S-Video), Audio In/Out and via Speaker, I/R Remote Control. **Options:** Glass Front. Other sizes available.

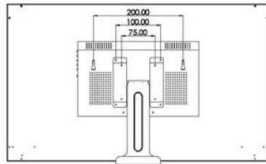

Main Features:

- Resolution: 1920 x 1080P – Full HD
- Picture Ratio: 16:9
- Brightness: 250 cd/m2 - LED Back light.
- Contrast Ratio: 3000:1
- Inputs: SDI, HDMI, DVI, VGA, S-Video Composite Video BNC, Audio.
- Outputs: SDI, Composite Video, Audio.
- Mounting: VESA 75 or 100, Key Hole, Stand.
- 3D De-Interlaced Technology.
- Anti-blur/image auto.
- Slim Aluminium cabinet in Black.
- Speaker 2 Watts max.
- USB for Media and Service use only.

The L240HMSDI with Full HD TFT technology offers Professional sharp images coupled with a high contrast ratio gives superb pictures. SDI In/Out, HDMI, DVI, Composite video In/Out with BNC Connectors makes this is a truly versatile Monitor. Also boasting various mounting options and finished in a Smart tough Aluminium Metal housing. This compact unit is ideal for Multimedia Video and Surveillance system applications.

SPECIFICATIONS:

- Active area: 527.04 x 294.16 (WxH)mm. • 16.7M Colours. • PAL and NTSC Auto.
- Response Time: 1.5/3.5 ms (Tr/Tf). • Viewing angle: Left/Right: 89°, Up/ Down 89°.
- SDI Standard: 3G-SDI (SMPTE 424M), HD-SDI (SMPTE 292M) SD-SDI (SMPTE 259M).
- SDI Video: 3G-1080P50/60 (4:2:2), HD-720P50/60 & 1080i50/60, 1080P25/30Hz, SD-NTSC/60Hz, PAL/50Hz.
- SDI Bandwidth: 2.97 Gbps, 2.975 / 1.001 Gbps.
- Controls/Indicators: Front: On LED, I/R sensor. Rear: Source, Menu, Item, Up, Down, Power.
- Power Source: 12V DC, 2.08 Amp, 27 Watts approx. AC Adaptor: 100-240 Vac 50/60Hz 1.5Amp.
- Dimensions: 585.6 x 353.1 x 47.1 (59 with stand). Carton: 650 x 500 x 180 (WxHxD)mm.
- Weight: Unit: 5.6 Kgms, Carton: 7.61 Kgms. • Temp: Operation: 0°C~50°C.

Connections: SDI In/Out: BNC sockets. HDMI: Type A Socket. DVI: DVI-D Socket. Composite Video In/Out: BNC sockets. VGA: 15 pin Sub-D. S-Video (Y/C) In: 4 pin mini din socket. Audio In/Out: 3.5mm jack sockets. DC input: 2.1mm socket. AC adaptor: IEC socket. USB for Media and Service use only.

Standard accessories: AC adapter, AC Mains Lead, I/R Remote Control.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO