

PSI Displays Ltd




Unit 4, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

LCD COLOUR MONITOR Model No. L57RHM

3 Monitors x 5.7" TFT LCD Colour Monitor with LED Back light, Metal Cased in 19" Rack Mounting. Inputs of HDMI x 2, DVI, VGA, Composite Video In/Out BNC sockets, S-Video. (Y/C), Audio In/Out and via speaker, USB for Media and Service use. I/R remote control.

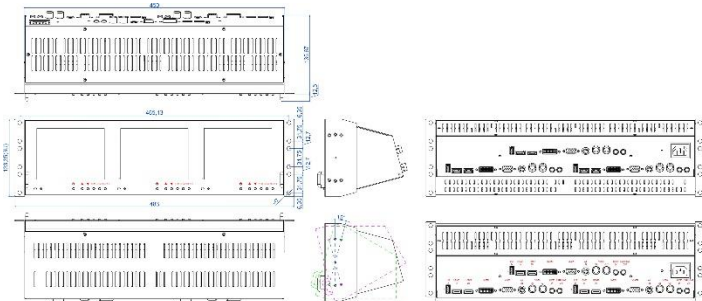

Main Features:

- Resolution: 640xRGBx480 pixels.
- Picture Ratio: 4:3
- Brightness: 700 cd/m2 LED Back Light.
- Contrast Ratio: 800:1
- Input: HDMI, VGA, DVI, S-Video Y/C, Composite Video BNC, Audio In/Out. USB for Media and Service use.
- Full OSD and Hot keys.
- Metal Cabinet finished in Black.
- Mounting: 19" Rack Mounting. 3U High.
- Single 240VAC Power connection.
- True 10bit Colour processing engine.
- ICM (Independent Colour Management).
- DCC (Dynamic Contrast control).

The L57RHM offers 3 Monitors of 5.7" TFT LCD in one rugged 19" rack mounting with Tilt 15/15° at 3U high. With Digital panel, Active Matrix technology and LED Backlight it offers a superb sharp and high contrast images. Individual On/Off switch and Full OSD with Hot keys. HDMI, VGA, DVI, S-Video Y/C and Composite Video In/Out BNC and Audio In/Out and out via Speaker. Single power connection 100-240volt operation. With universal application potential, the unit is ideal for surveillance systems, monitoring systems and multimedia video applications.

SPECIFICATIONS:

- Active area: 115.2 x 86.4 (WxH)mm. • 262K Colours. • PAL and NTSC Auto.
- Response Time: 15/10ms (Tr / Tf). • Viewing angle: Left/Right: 70°, Up/Down: 80°.
- Controls: Full OSD via Menu, Up, Down, Power On/Off, On LED.
- Dot Pitch: 0.18 x 0.18 (WxH)mm. • Power Source: 100-240 VAC, 21Watts approx.
- Dimensions: 483 x 133.35 x 135.67 19" Rack by 3U High. Carton: 510 x 215 x 180.(WxHxD)mm.
- Weight: Unit: 3.2 Kgms, Carton: 5 Kgms. • Temp: Operation: -10°C~60°C.

Connections: Each Monitor: Input: HDMI x 2: Type A socket. DVI: DVI-D socket, VGA: 15 pin Sub-D. Composite Video In/Out: BNC socket. S-Video (Y/C) In: 4 pin mini din socket. Audio In/Out: 3.5mm Jack sockets. USB: Type A for Media and Service use only. Power: Single IEC mains socket powering both monitors.

Standard accessories: UK AC Mains Lead, I/R Remote Control.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO