

acer

PROJECT WITH
CLARITY



Acer X1526

Full HD (1920 x 1080)

4,000 ANSI lumens

Image Shift& 24/7

Up to 20,000-hour lamp life



Resolution



Brightness



Contrast Ratio



Lamp life



ISFccc certified

Product Specifications

Model name	X1526
Projection system	DLP®
Resolution	1080p (1,920 x 1,080) Maximum WUXGA (1,920 x 1,200)
Brightness	4,000 ANSI Lumens (Standard), 3,200 ANSI Lumens (ECO),(Compliant with ISO 21118 standard)
Aspect ratio	16:9 (Native), 4:3 (Supported)
Contrast ratio	13,000:1 Dynamic Black
Throw ratio	1.49 ~ 1.64 (61"@2m)
Zoom ratio	1.1X
Projection lens	F = 2.56 ~ 2.68, F = 22mm ~ 24.1mm, Manual Zoom & Focus
Lamp life	5,000 Hours (Standard), 10,000 Hours (ECO), 20,000 Hours (EcoPro mode)
Noise level	29 dBA (ECO)
Audio	3W x1
Input interface	HDMI1.4a (HDCP 1.4) x 2
Output interface	PC Audio (3.5mm mini jack) x 1 DC Out (5V/1.5A, USB Type A) x 1
Control interface	USB (Type A) x 1, share output port RS232 (D-sub) x 1
Dimensions	299.5 x 220 x 105.1 mm(11.8" x 8.7" x 4.1")
Weight	2.4 Kg (5.29 lbs)

Feature Highlights

Expressive Display

- Full HD (1,920 x 1,080)
- 4,000 ANSI lumens brightness
- Dynamic Black 13,000:1
- Acer LumiSense smart detection
- Acer ColorBoost3D brings true-to color
- Acer ColorSafe II prevents color de
- Acer BlueLight Shield
- HDMI 3D

Enhanced Usability

- ISFccc certificated
- HDMI CEC control
- Low input lag
- Wireless Projection (optional)
- 3W built-in speaker
- Acer Display Widget


Installation flexibility

- Image shift
- Auto Keystone Correction
- Auto Ceiling-mounted Correction
- AC power on
- 24/7 operation

Eco-friendly Functionality

- Acer EcoProjection reduced up to 70% power consumption.
- Up to 20,000 hours lamp life (EcoPro mode)

Product View

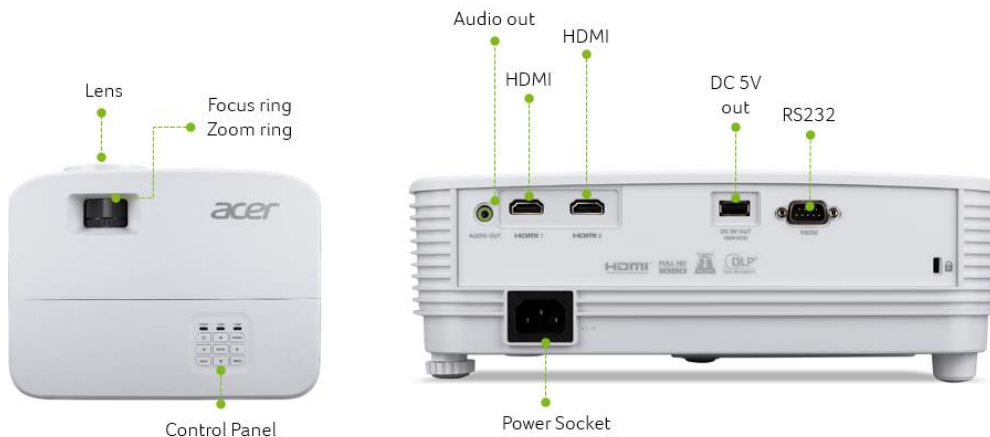

Optional Accessory



Brightness

4,000 lumens high brightness

4,000 lumens high brightness provides the ability to project crystal clear, vibrant images from a long distance on a large screen even in daytime indoors.



Resolution

Full HD (1920 x 1080) resolution

1080p (1920x1080) is a set of HDTV high-definition video modes. With the superb clarity of available 1080p Full HD, you'll enjoy exceptional details no matter on Blu-ray movies, video games or business presentation.



Image Shift

Image Shift

Project with precision by utilizing the innovative Image Shift. Combining the digital zoom1 & Image Shift, you will be able to shift the image precisely in screen without redecorating existed mounting location. It also helps you avoid the keystone distortion



24/7 Operation

24/7

X1526 supports 24 hours-7 days of continuous projection when prolonged periods of use is required. This is especially useful for public display or museum exhibition.

About Acer

Founded in 1976, today Acer is one of the world's top ICT companies and has a presence in over 160 countries. As Acer looks into the future, it is focused on enabling a world where hardware, software and services will infuse with one another to open up new possibilities for consumers and businesses alike. From service-oriented technologies to the Internet of Things to gaming and virtual reality, Acer's 7,000+ employees are dedicated to the research, design, marketing, sale, and support of products and solutions that break barriers between people and technology. More information is at www.acer.com.

