


[Home](#) → [Adapters](#) → [In-Series](#)

 


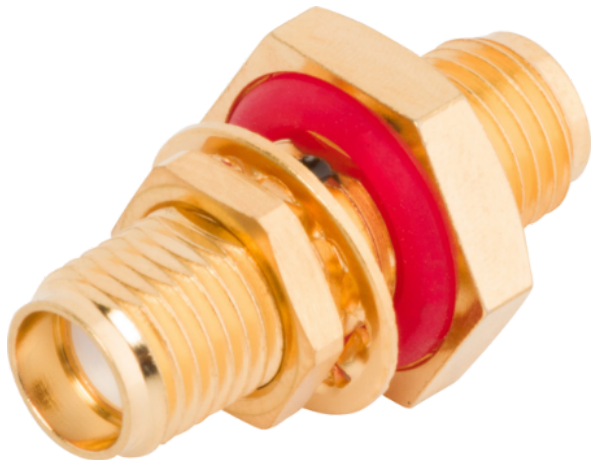

SMA Female to Female Bulkhead Hermetic Adapter

P/N: 2991-6002

IN STOCK AT	QTY	ORDER
CW Swift & Associates	1638	BUY NOW
Mouser Electronics	68	BUY NOW
Newark	47	BUY NOW
Digi-Key Electronics	41	BUY NOW
Interstate Connecting Components	6	BUY NOW
Heilind Electronics	2	BUY NOW



Downloads



SPECIFICATIONS

COMPLIANCE

CONTACT US

RF Series	SMA
Gender	Jack (Female)
Orientation (Body)	Straight
Body Style	Jamnut/Bulkhead
Style	Hermetic
Coupling	Threaded
Mounting Type	Panel
IP Rating	IP 68



RF Series 2	SMA
Finish	Gold
Gender 2	Jack (Female)
Orientation 2 (Body)	Straight
Electrical	
Frequency	18 GHz
Impedance	50 ohms
Shielding Effectiveness	≥ -90 dB
Dielectric withstanding Voltage	1000 VRMS
Mechanical	
Mating Cycles	500
Mating Torque	7 - 10 in - lbs
Intermateability	2.92mm
Environmental	



Temperature Rating	-65°C to +165°C
Corrosion (salt spray)	MIL-STD-202, Method 101, Condition B
Vibration	MIL-STD-202, Method 204, Condition D
Shock	MIL-STD-202, Method 213, Condition I
Thermal Shock	MIL-STD-202, Method 107, Condition B
Moisture Resistance	MIL-STD-202, Method 106, Less Step 7B
Barometric Pressure (Altitude)	MIL-STD-202, Method 105, Condition C, 70k Ft.

CUSTOMERS ALSO VIEWED

