


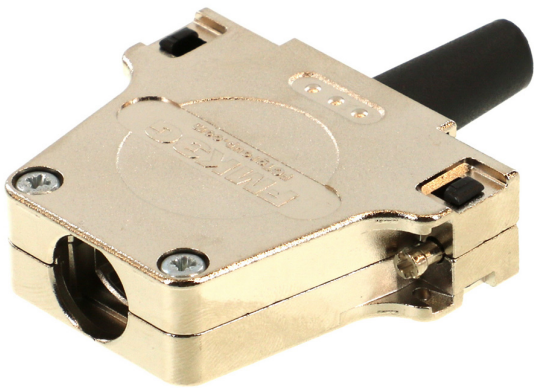

Part Number : [1731110058](#)
Product Description : FCT Metal Backshell for D-Sub Connector, Shell Size 3, Straight Large Diameter Cable Outlet, Large Inner Chamber, with Rubber Bushing and #4-40 Locking Screws
Series Number : 173111
Status : Active
Product Category : D-Sub Backshells
Engineering Number : FMK3G-K201




Documents & Resources

- Drawings**
[Drawing 1731110058_sd.pdf](#)
- 3D Models and Design Files**
[3D Model 1731110058_stp.zip](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 47; 34; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

- [Multiple Part Product Compliance Statements](#)
- Eu RoHS
 - REACH SVHC
 - Low-Halogen
- [Multiple Part Industry Compliance Documents](#)
- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	D-Sub Backshells
Series	173111
Description	FCT Metal Backshell for D-Sub Connector, Shell Size 3, Straight Large Diameter Cable Outlet, Large Inner Chamber, with Rubber Bushing and #4-40 Locking Screws
Magnetic	Yes
Product Family	FCT D-Sub Connectors
Product Name	FCT Products
Type	Rugged Metal
UPC	889056411615

Electrical

Shield Type	Solid Metal
Shielded	Yes

Physical

Cable Diameter	8.00-12.50mm
Material - Backshell	Zinc Die-cast
Material - Bushing	TPE
Material - Screw	Steel
Mounting Style	Locking Screw
Orientation	Straight
Packaging Type	Carton
Plating - Backshell	Nickel
Temperature Range - Operating	-35° to +100°C
Thread Size	4-40 UNC

Thread Type	Standard
Tightening Test Torque	40 Ncm
Waterproof / Dustproof	No

Use with Part(s)

Description	Part Number
Use With	FCT D-Sub, Size 3