




Part Number : [459842113](#)

Product Description : DuraClik Wire-to-Board Independent Secondary Lock (ISL) Retainer, 15 Circuits, Gray

Series Number : 560125

Status : Active

Product Category : Connector Accessories

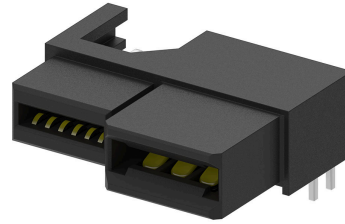

Documents & Resources

Drawings

[5601251500_sd.pdf](#)

3D Models and Design Files

[5601251500_stp.zip](#)

Specifications

[PS-560123-001-001.pdf](#)

[PS-560123-003-001.pdf](#)

[5601240131-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Accessories
Series	560125
Description	DuraClik Wire-to-Board Independent Secondary Lock (ISL) Retainer, 15 Circuits, Gray
Application	Automotive
Component Type	Independent Secondary Lock
Product Name	DuraClik
UPC	196823402074

Physical

Circuits (Loaded)	15
Circuits (maximum)	15
Color - Resin	Gray
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	134.725/mg
Number of Rows	1
Packaging Type	Bag
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +130°C

Use with Part(s)

Description	Part Number
DuraClik ISL Wire-to-Board Receptacle Housing, Single Row, White, 15 Circuits	<u>5601231500</u>

This document was generated on Oct 11, 2024