


## Data Sheet | Item Number: 211-835

Cable tie marker; for Smart Printer; for use with cable ties; 25 x 11 mm; white

<https://www.wago.com/211-835>

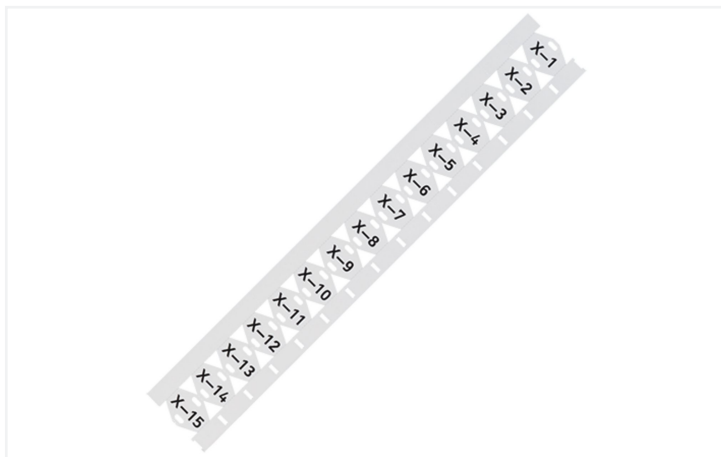

Color: ■ white

### Technical data

Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	500 pcs/reel; 1 line
Printing device	Smart Printer (thermal transfer printer)

### Physical data

Height	20 mm
Width	25 mm
Depth	0.17 mm
Marking surface	25 x 11 mm

### Mechanical data

Mounting type	Mounting with cable ties
Smear resistance	in conjunction with 258-5005 Ink Ribbon

### Material data

Color	white
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	without adhesive
Halogen-free	Yes
Weight	129.5 g
Fire load	0 MJ

Environmental requirements	
Ambient temperature (storage)	+10 ... +21 °C
Ambient temperature (operation)	-40 ... +150 °C
Relative humidity	40 ... 50 %

Commercial data	
Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-04-01
eCl@ss 9.0	27-40-06-29
ETIM 9.0	EC001530
ETIM 8.0	EC001530
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821688648
Customs tariff number	39269097900

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

## Downloads

### Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 211-835	↓

## Documentation

Operating Instructions			
211-835 Information on printing material	1	pdf	↓
	28.08.2020	1380.62 KB	

## 1 Compatible Products

### 1.2 Optional Accessories

#### 1.2.1 Marking

##### 1.2.1.1 Marking device



**Item No.: 258-5000**  
 Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: [www.wago.com](http://www.wago.com)